


E11158



Wirable plug

SSTGF030ZDSFKPK

Article no longer available - archive entry

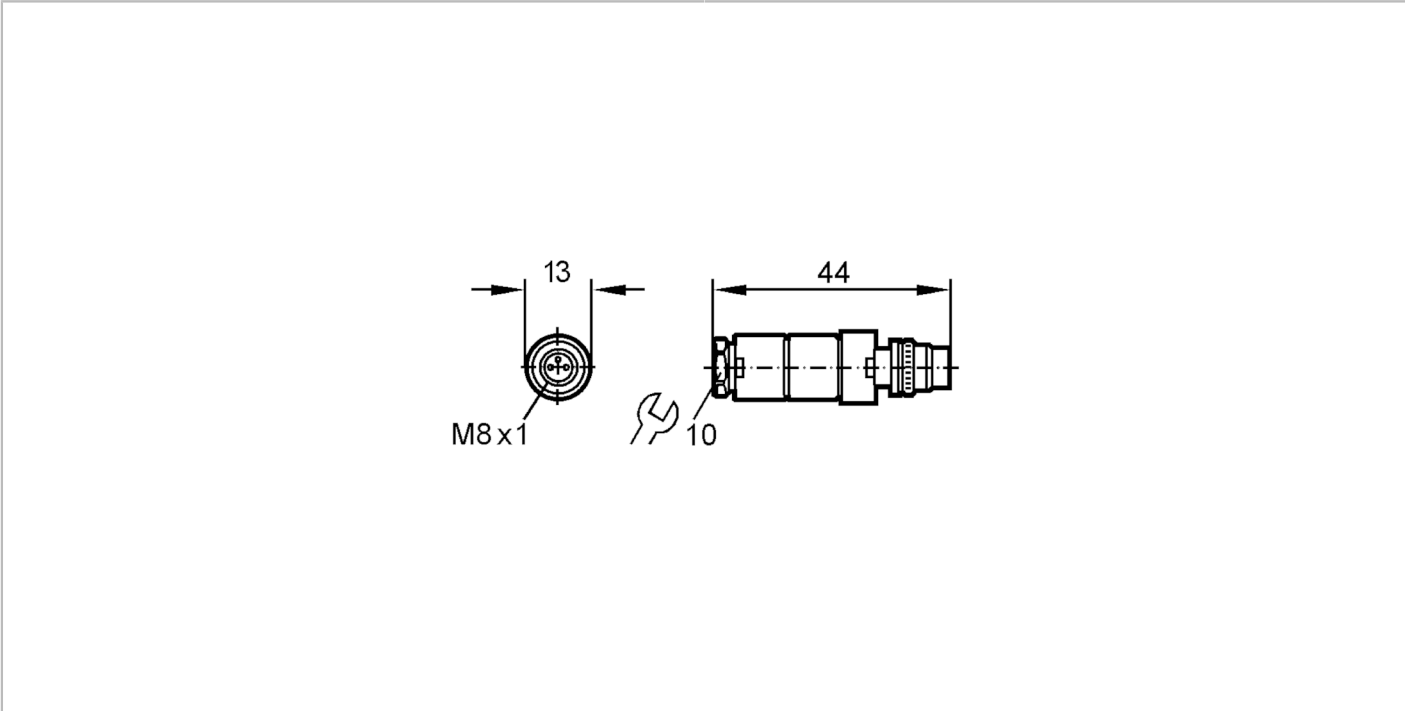

Electrical data		
Operating voltage	[V]	< 60 AC/DC
Protection class		III

Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 67

Mechanical data		
Dimensions	[mm]	13 x 13 x 44
Material		PA
Molded-body material		PA
Material nut		ZnAl / Ni

Remarks		
Pack quantity		1 pcs.

Electrical connection		
insulation displacement technology: 0.14...0.34 mm²; Core insulation: PVC / PETP; (Ø 1.0...1.55 mm); Cable sheath: Ø 4...5 mm		

Electrical connection - plug		
Connector: 1 x M8, straight; coding: A; Moulded body: PA; Locking: ZnAl / Ni		



E11158

Wirable plug

SSTGF030ZDSFKPK



Connection

