


E11168



Patchcords with valve plug

VSGH030MSS0001HDOAB031PLS

Article no longer available - archive entry

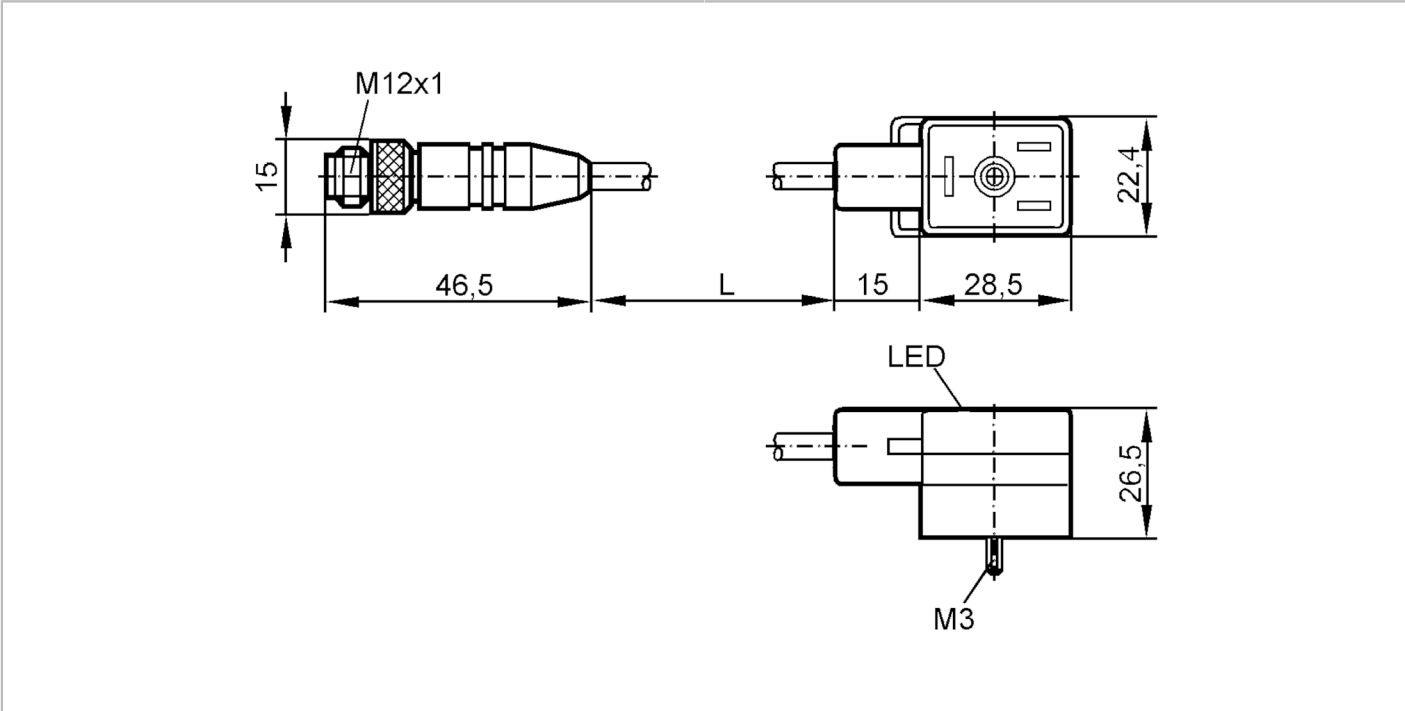

Application		
System		Halogen-free
Electrical data		
Operating voltage	[V]	< 24 AC/DC
Overvoltage protection		yes; (VDR)
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Displays / operating elements		
Display	Switching status	1 x LED, yellow
Accessories		
Items supplied		screw
		panel for labelling
Remarks		
Pack quantity		1 pcs.

E11168

 


Patchcords with valve plug

VSGH030MSS0001HDOAB031PLS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Electrical connection

Cable: 1 m, PUR, Halogen-free, grey; 3 x 0.5 mm²

Connection

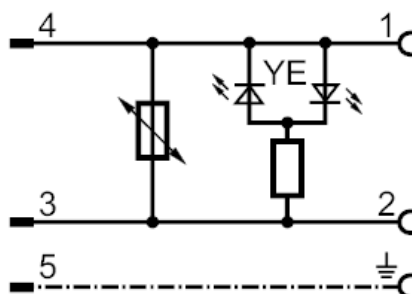

Electrical connection - Socket

Connector: 1 x valve type B industrial standard, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

