


E11177



Female cordset

ADOAH040MSS0025H04

Article no longer available - archive entry

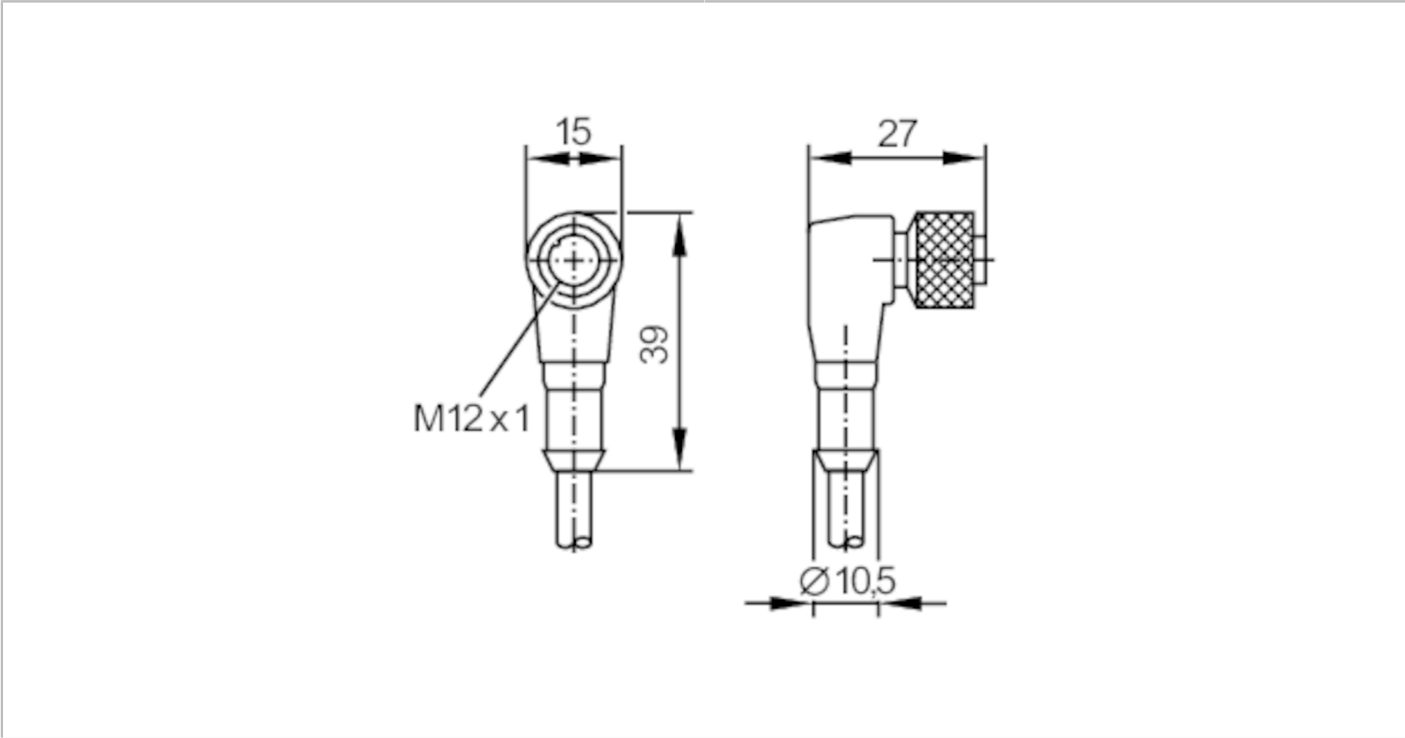

Application		
System		Free from silicone; Halogen-free; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E11177



Female cordset

ADOAH040MSS0025H04

Electrical connection


Cable: 25 m, PUR, Halogen-free, grey, Ø 5 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Contacts: gold-plated



Connection

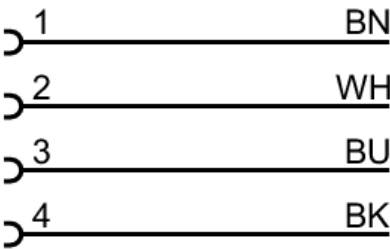

BK =	Core colors :
BN =	black
BU =	brown
WH =	blue
	white