

E11181




Patchcords with valve plug

VVDAB031--S00,6H03STGH030MSS

Article no longer available - archive entry

Alternative articles: E11432

When selecting an alternative article and accessories please note that technical data may differ!

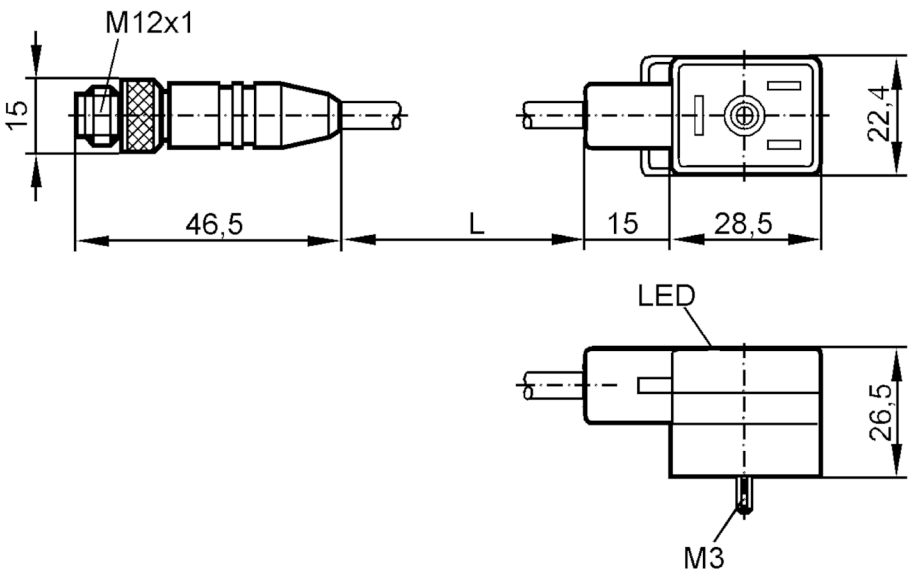

Application

System	Halogen-free
--------	--------------

Electrical data

Operating voltage [V]	< 24 AC/DC
Overvoltage protection	yes; (VDR)

Operating conditions

Ambient temperature [°C]	-25...90
Protection	IP 67

Mechanical data

Material	TPU (urethane)
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated

Displays / operating elements

Display	Switching status	1 x LED, yellow
---------	------------------	-----------------

Accessories

Items supplied	screw
	panel for labelling

Remarks

Pack quantity	1 pcs.
---------------	--------

E11181




Patchcords with valve plug

VVDAB031--S00,6H03STGH030MSS

Electrical connection - plug

 
Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Electrical connection

Cable: 0.6 m, PUR, Halogen-free, black; 3 x 0.5 mm²

Connection

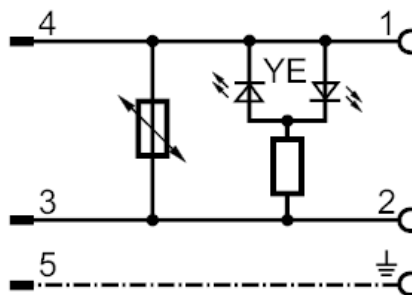

Electrical connection - Socket

Connector: 1 x valve type B industrial standard, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

