


E11185



Patchcords with valve plug

VVSAB031--S0003H03STGH030MSS

Article no longer available - archive entry

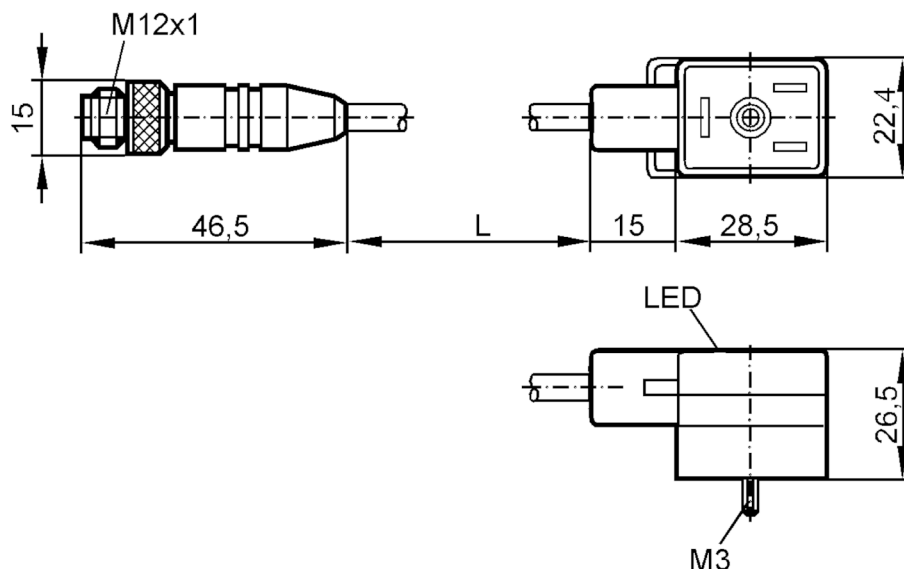

Application

System Halogen-free

Electrical data

Operating voltage [V] < 24 AC/DC

Overvoltage protection yes; (VDR)

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Material TPU (urethane)

Molded-body material TPU (urethane)

Material nut brass, nickel-plated

Displays / operating elements

Display Switching status 1 x LED, yellow

Accessories

Items supplied screw
panel for labelling

Remarks

Pack quantity 1 pcs.




Patchcords with valve plug

VVSAB031--S0003H03STGH030MSS

Electrical connection - plug

 
Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Electrical connection

Cable: 3 m, PUR, Halogen-free, black; 3 x 0.5 mm²

Connection

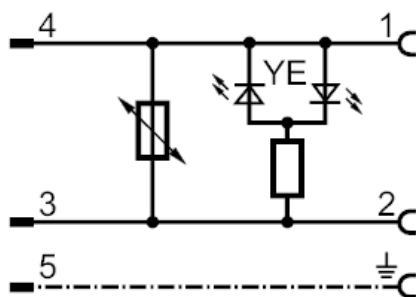

Electrical connection - Socket

Connector: 1 x valve type B industrial standard, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

