




Female cordset

ADOGG040--S0005A03

Article no longer available - archive entry

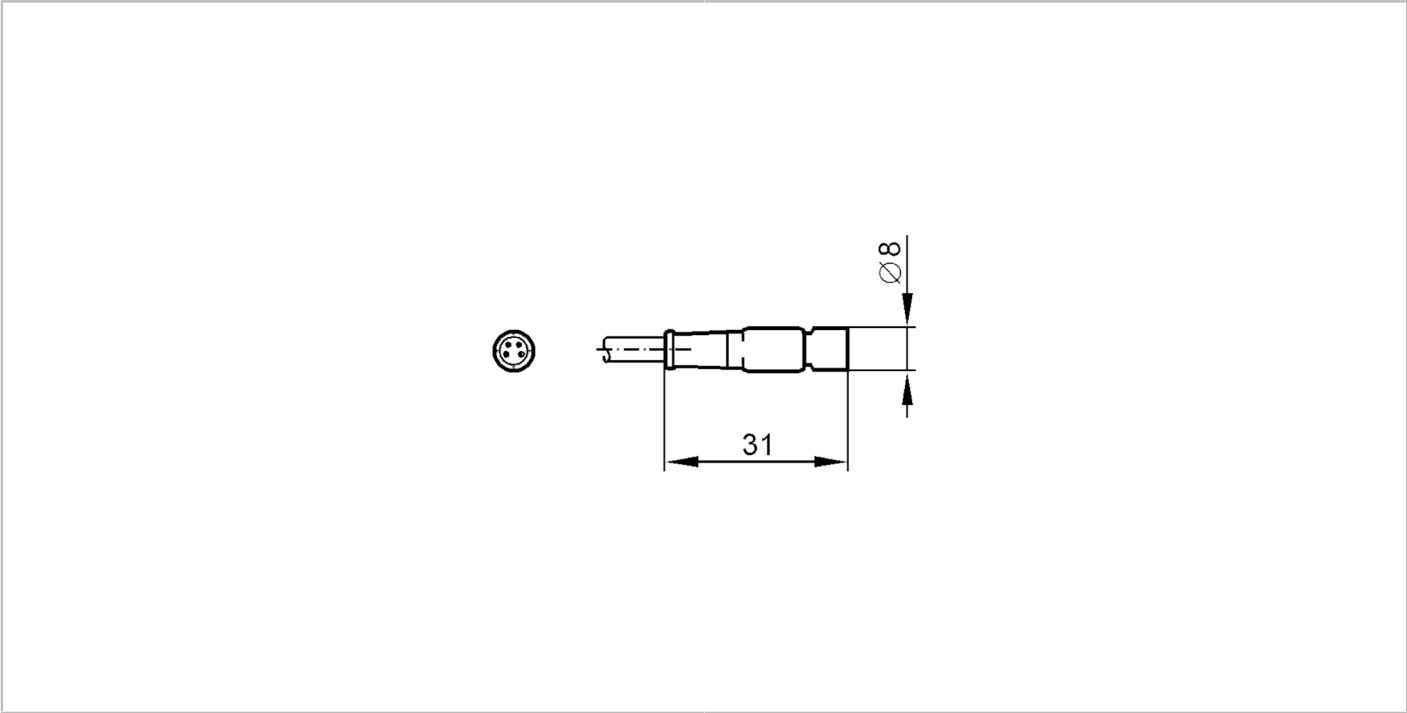

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 65

Mechanical data

Dimensions	[mm]	8 x 8 x 31
Material		TPU (urethane)
Molded-body material		TPU (urethane)

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

Cable: 5 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane)
Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane)




E11189



Female cordset

ADOGG040--S0005A03

Connection

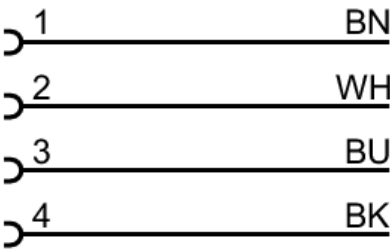

	Core colors :
BK =	black
BN =	brown
BU =	blue
WH =	white