




Connection cable

VDOGH080MSS01,5A06STGH080MSS

Article no longer available - archive entry

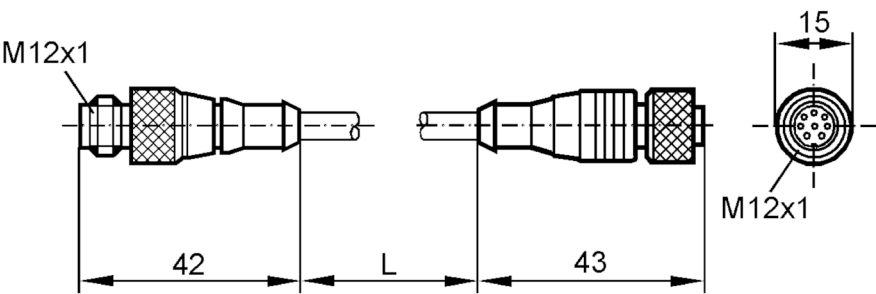

Application	
System	Free from silicone; Halogen-free; gold-plated contacts
Free from silicone	yes

Electrical data	
Operating voltage [V]	10...30 DC


Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 67

Mechanical data	
Material	TPU (urethane)
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated

Remarks	
Pack quantity	1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.5 Nm

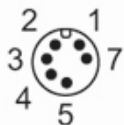

E11192




Connection cable

VDOGH080MSS01,5A06STGH080MSS

Electrical connection

Cable: 1.5 m, PUR / PVC, Halogen-free; 6 x 0.34 mm² (42 x Ø 0.1 mm)

Connection

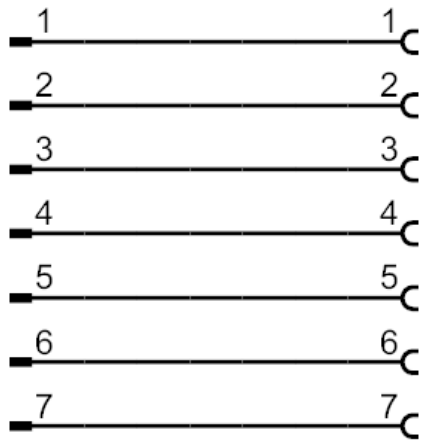

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.5 Nm

