


# E11194



## Male receptacle

ESTGH080MSS00,5E08 (PG9)

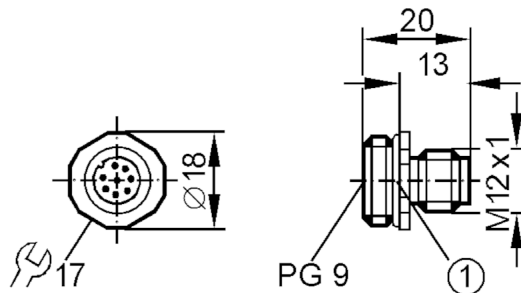

1 O-ring



| Electrical data   |      |                                     |
|---|------|-------------------------------------|
| Operating voltage   | [V]  | < 50 AC / < 75 DC                   |
| Operating conditions  |      |                                     |
| Ambient temperature   | [°C] | -25...85                            |
| Protection  |      | IP 68                               |
| Mechanical data   |      |                                     |
| Weight  | [g]  | 38.473                              |
| Mounting thread   |      | PG 9                                |
| Material  |      | housing: diecast zinc nickel-plated |
| Remarks   |      |                                     |
| Pack quantity   |      | 1 pcs.                              |
| Electrical connection   |      |                                     |
| Cable: 0.5 m, PVC; 8 x 0.25 mm <sup>2</sup> (14 x Ø 0.15 mm ) |      |                                     |
| Electrical connection - plug                                  |      |                                     |
| Connector: 1 x M12, straight; coding: A; Contacts: 8          |      |                                     |
|   |      |                                     |

# E11194



## Male receptacle

ESTGH080MSS00,5E08 (PG9)

### Connection

|   |    |
|---|----|
| 1 | WH |
| 2 | BN |
| 3 | GN |
| 4 | YE |
| 5 | GY |
| 6 | PK |
| 7 | BU |
| 8 | RD |

Colors to DIN 47100

Core colors :

|      |        |
|------|--------|
| BN = | brown  |
| BU = | blue   |
| GN = | green  |
| GY = | grey   |
| PK = | pink   |
| RD = | red    |
| WH = | white  |
| YE = | yellow |