


E11194



Male receptacle

ESTGH080MSS00,5E08 (PG9)

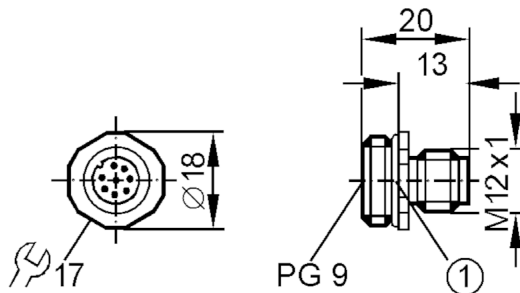

1 O-ring

 


Application	
Application	Industrial applications
Electrical data	
Operating voltage [V]	< 50 AC / < 75 DC
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 68
Mechanical data	
Weight [g]	38.473
Mounting thread	PG 9
Material	housing: diecast zinc nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection	
Cable: 0.5 m, PVC; 8 x 0.25 mm ² (14 x Ø 0.15 mm)	

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Contacts: 8



E11194



Male receptacle

ESTGH080MSS00,5E08 (PG9)

Connection

1	WH
2	BN
3	GN
4	YE
5	GY
6	PK
7	BU
8	RD

Colors to DIN 47100

Core colors :

BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow