

E11216




Wiring block

ZDO4F035MSS0000-STGH080MSS

Article no longer available - archive entry

Alternative articles: EBC050
When selecting an alternative article and accessories please note that technical data may differ!

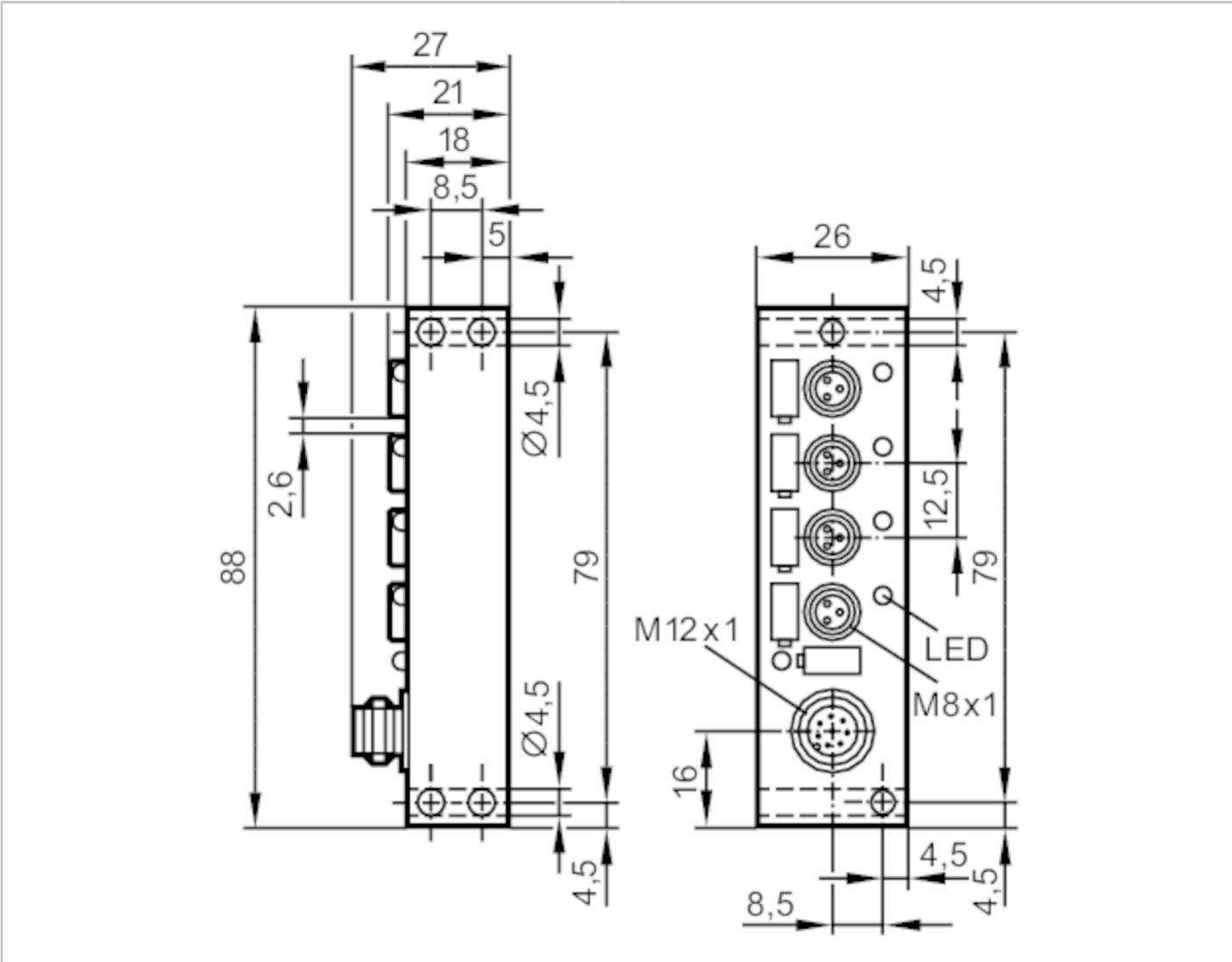

Application		
System		gold-plated contacts
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		III
Max. current load per module/slot	[A]	2
Max. current load total	[A]	6
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Weight	[g]	81.6

E11216



Wiring block

ZDO4F035MSS0000-STGH080MSS


Material	PBT-GF20; brass nickel-plated
Molded-body material	PBT-GF 20 / brass, nickel-plated
Number of ports splitter box	4
Connector type	M8

Displays / operating elements		
Display	Switching status	4 x LED, yellow
	Power	1 x LED, green


Remarks	
Pack quantity	1 pcs.

Electrical connection - Connection

Connector: 1 x M12; coding: A; Moulded body: PBT-GF 20 / brass, nickel-plated; Contacts: gold-plated

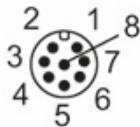

Connection

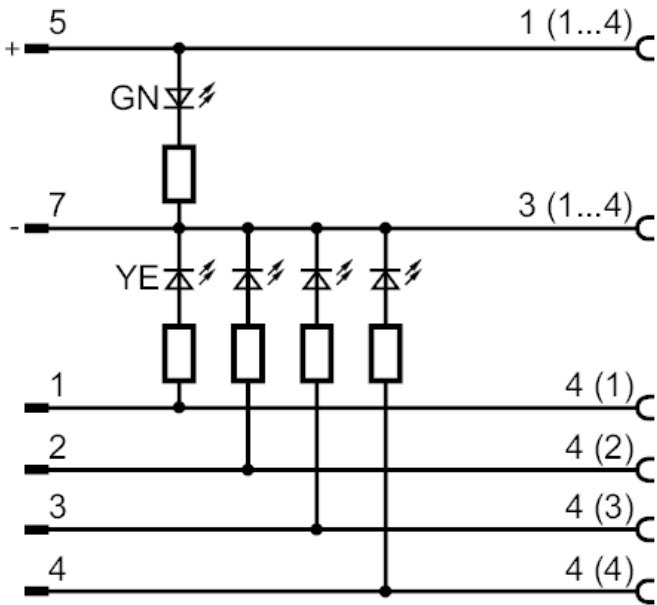

E11216



Wiring block

ZDO4F035MSS0000-STGH080MSS

Electrical connection - slot

Connector: 4 x M8; coding: A; Moulded body: PBT-GF 20 / brass, nickel-plated; Contacts: gold-plated

