




Wiring block

ZDO4F049MSS0000-STGO120MSS

Article no longer available - archive entry

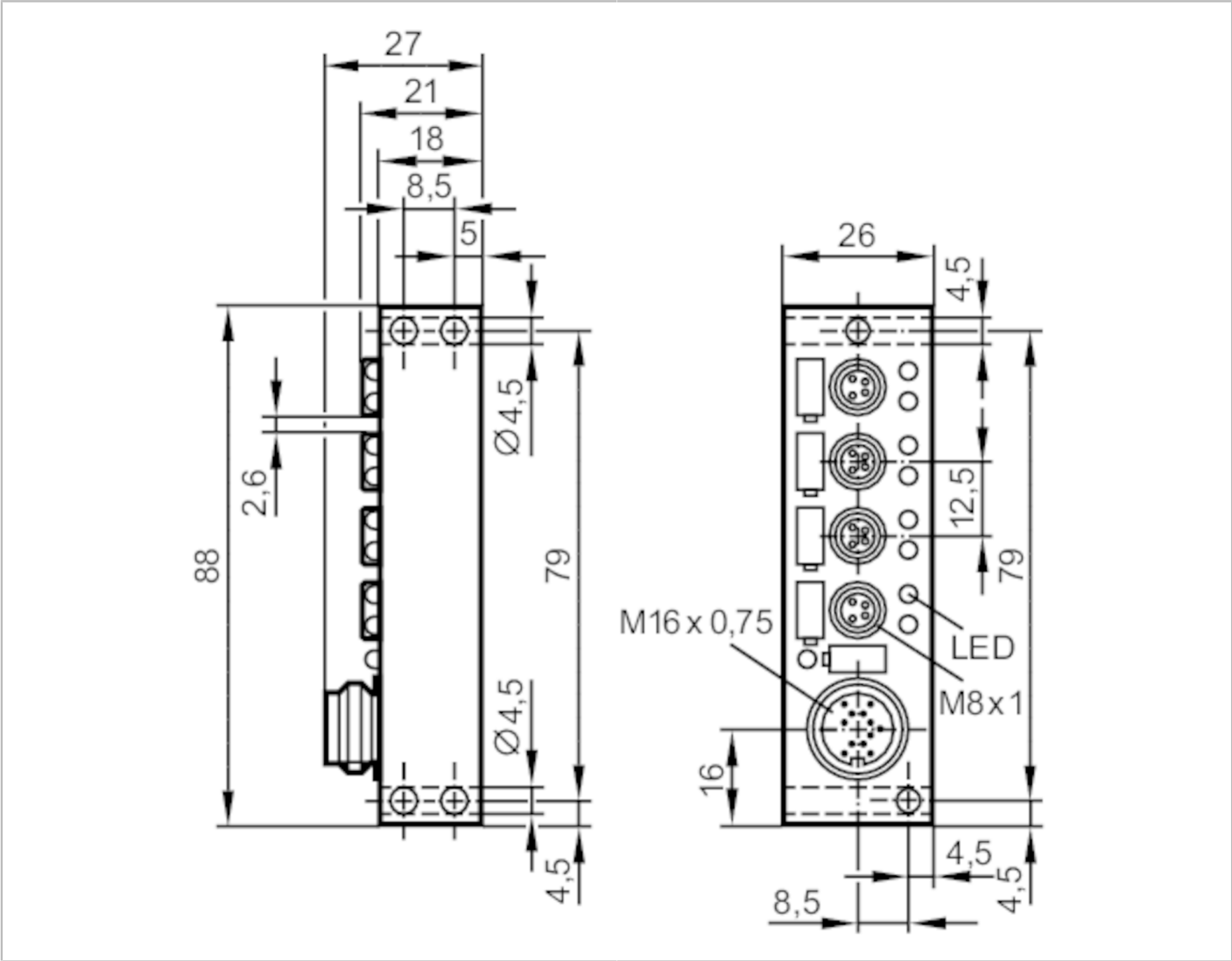

Application		
System		gold-plated contacts
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		III
Max. current load per module/slot	[A]	2
Max. current load total	[A]	6
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Weight	[g]	85.8
Material		PBT-GF20; brass nickel-plated
Molded-body material		PBT-GF 20 / brass, nickel-plated

E11219



Wiring block

ZDO4F049MSS0000-STGO120MSS

Number of ports splitter box	4
Connector type	M8

Displays / operating elements


Display	Switching status	8 x LED, yellow
	Power	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - Connection


Connector: 1 x M16; Moulded body: PBT-GF 20 / brass, nickel-plated; Contacts: gold-plated

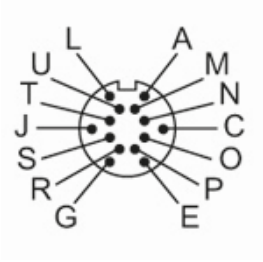

Wiring block

ZDO4F049MSS0000-STGO120MSS

Connection

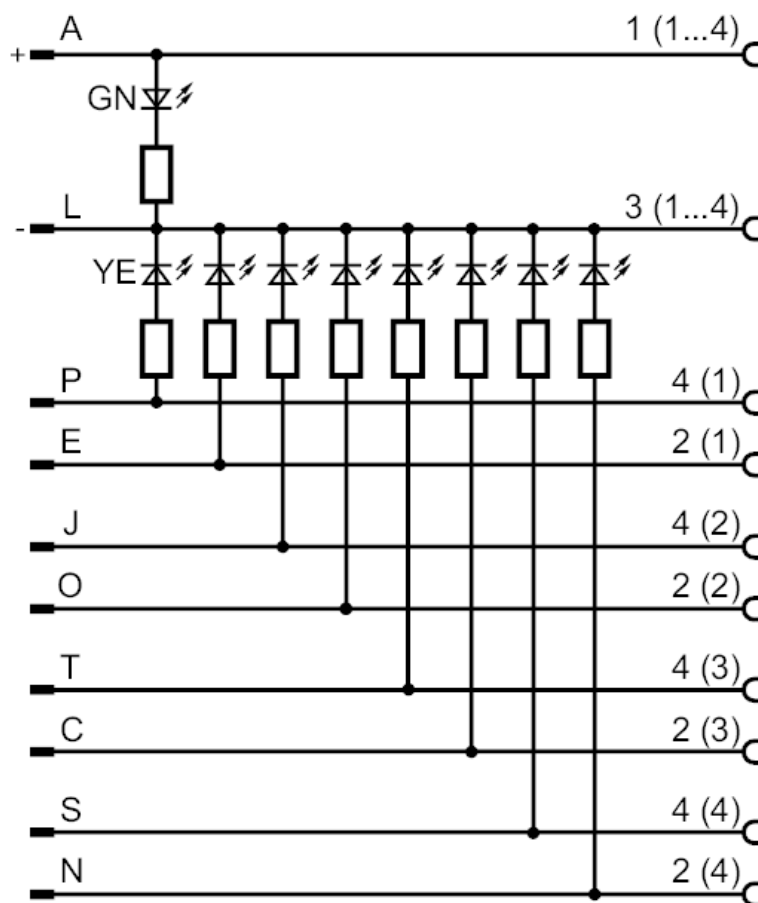

Electrical connection - slot

Connector: 4 x M8; coding: A; Moulded body: PBT-GF 20 / brass, nickel-plated; Contacts: gold-plated

