

E11225



Female cordset

ADOGF040VAS0025E04

Article no longer available - archive entry

Alternative articles: EVT137

When selecting an alternative article and accessories please note that technical data may differ!



Application

System	Free from silicone
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III
Max. current load total	[A]	3

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Weight	[g]	896.4
Dimensions	[mm]	10 x 10 x 31
Material		PVC
Molded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E11225



Female cordset

ADOGF040VAS0025E04


Electrical connection

Cable: 25 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)


Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Tightening torque: 0.6...0.7 Nm

Connector: 1 x M8, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Tightening torque: 0.6...0.7 Nm

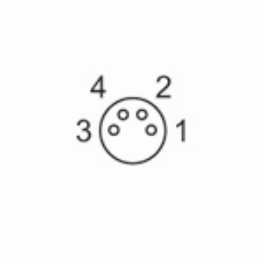

Connection

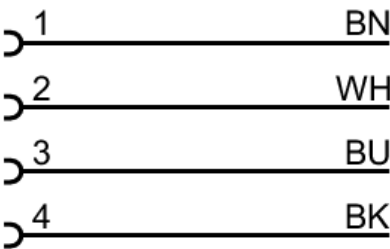

Core colors :
BK = black
BN = brown
BU = blue
WH = white