


# E11226



## Female cordset

ADOAO140MSS0005H10

Article no longer available - archive entry

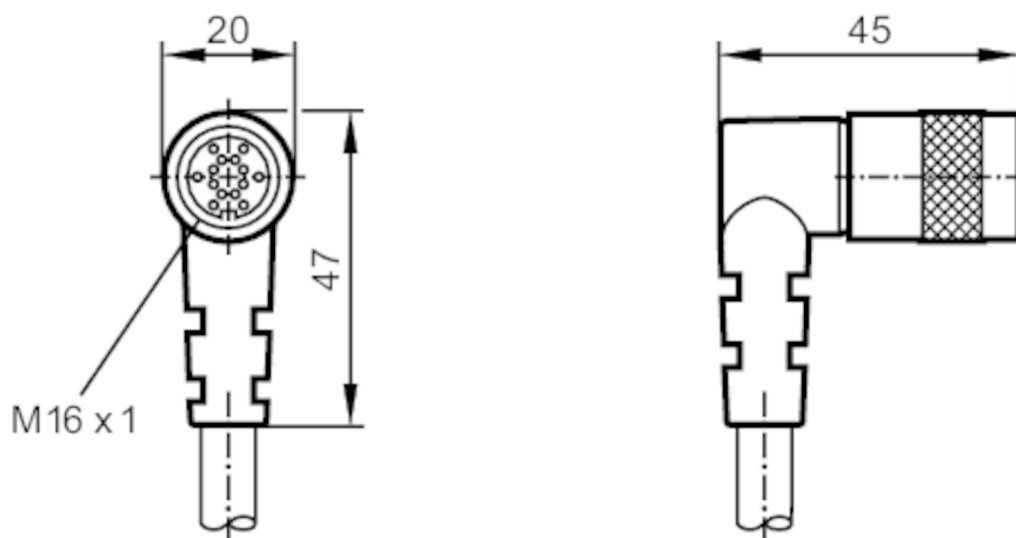

### Application

|                    |                                                          |
|--------------------|----------------------------------------------------------|
| System             | Free from silicone; Halogen-free; Drag chain suitability |
| Free from silicone | yes                                                      |

### Electrical data

|                         |     |         |
|-------------------------|-----|---------|
| Operating voltage       | [V] | < 30 DC |
| Max. current load total | [A] | 3       |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...80 |
| Protection          |      | IP 67    |

### Mechanical data

|                        |                                          |                                                                                                |
|------------------------|------------------------------------------|------------------------------------------------------------------------------------------------|
| Weight                 | [g]                                      | 579                                                                                            |
| Dimensions             | [mm]                                     | 45 x 20 x 47                                                                                   |
| Material               |                                          | PUR                                                                                            |
| Molded-body material   |                                          | PUR                                                                                            |
| Material nut           |                                          | brass, nickel-plated                                                                           |
| Drag chain suitability |                                          | yes                                                                                            |
| Drag chain suitability | Bending radius for flexible applications | min. 12.5 x cable diameter                                                                     |
|                        | Travel speed                             | max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s <sup>2</sup> |
|                        | Torsional strain                         | ± 180 °/m                                                                                      |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

# E11226



## Female cordset


ADOAO140MSS0005H10

### Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 9.2 mm; 8 x 0.34 mm<sup>2</sup> + 2 x 0.75 mm<sup>2</sup>

### Electrical connection - Socket

Connector: 1 x M16, angled; Moulded body: PUR; Locking: brass, nickel-plated

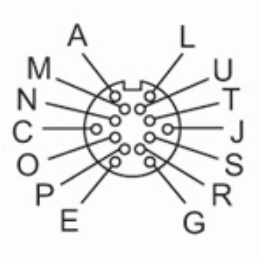

### Connection

|   |       |
|---|-------|
| A | BN    |
| C | WH/GN |
| E | GY/PK |
| J | GN    |
| L | BU    |
| N | GN/BN |
| O | RD/BU |
| P | WH    |
| S | GY    |
| T | YE    |

|      |               |
|------|---------------|
| U:   | not used      |
| R:   | not used      |
| G:   | not used      |
| M:   | not used      |
|      | Core colors : |
| BN = | brown         |
| BU = | blue          |
| GN = | green         |
| GY = | grey          |
| PK = | pink          |
| RD = | red           |
| WH = | white         |
| YE = | yellow        |