


E11230



Connection cable


VDOGH080MSS0005H08STGH080MSS

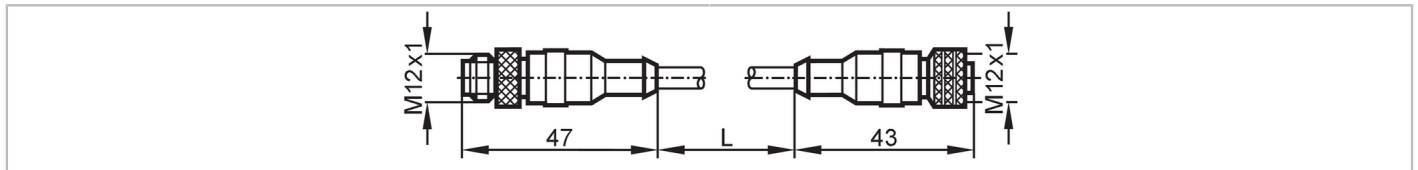

Application	
Special feature	Halogen-free
Application	Industrial applications
Electrical data	
Operating voltage [V]	< 30 AC / < 36 DC
Operating conditions	
Ambient temperature [°C]	-25...80
Protection	IP 68
Mechanical data	
Weight [g]	331.8
Molded-body material	PUR
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection - plug

 
Connector: 1 x M12, straight; coding: A; Contacts: 8; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm



Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 6.8 mm; 8 x 0.25 mm²

Connection

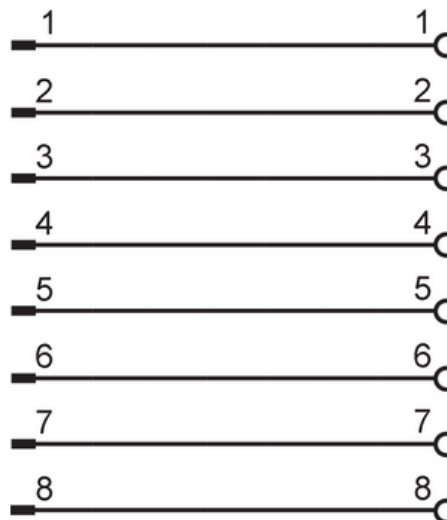

E11230



Connection cable

VDOGH080MSS0005H08STGH080MSS

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Contacts: 8; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm

