




Male cordsets

ASTGH050MSS0002H05

Article no longer available - archive entry

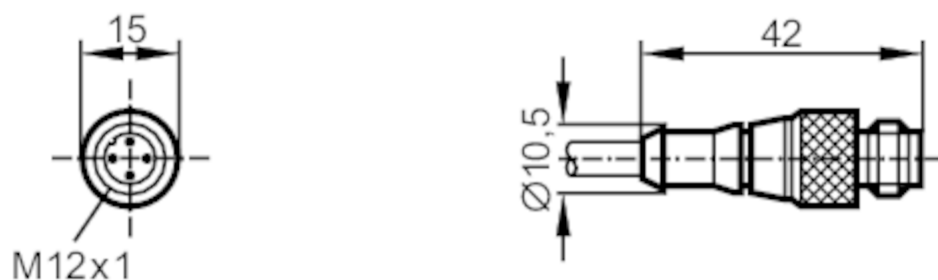

Application

System

Halogen-free

Electrical data

Operating voltage

[V]

< 30 AC / < 36 DC

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Dimensions

[mm]

15 x 15 x 42

Material

TPU (urethane)

Molded-body material

TPU (urethane)

Material nut

brass, nickel-plated

Remarks

Pack quantity

1 pcs.

E11253



Male cordsets


ASTGH050MSS0002H05

Electrical connection

Cable: 2 m, PUR, Halogen-free, black, Ø 5.6 mm; 5 x 0.5 mm² (16 x Ø 0.2 mm)

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

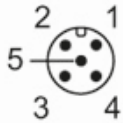

Connection

1	BN
2	WH
3	BU
4	BK
5	GN/YE

	Core colors :
BK =	black
BN =	brown
BU =	blue
GN =	green
WH =	white
YE =	yellow