


Male cordsets

ASTGH030VAS0001A03

Article no longer available - archive entry

Alternative articles: EVC076

When selecting an alternative article and accessories please note that technical data may differ!

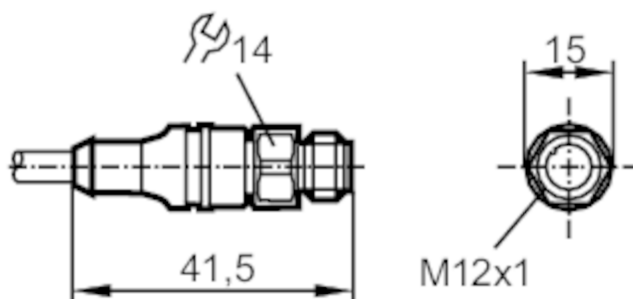

Application

System	Free from silicone
Free from silicone	yes

Electrical data

Operating voltage [V]	< 250 AC / < 300 DC
-----------------------	---------------------

Operating conditions

Ambient temperature [°C]	-25...70
Protection	IP 67

Mechanical data

Dimensions [mm]	15 x 15 x 41.5
Material	PVC
Molded-body material	PVC
Material nut	stainless steel (1.4404 / 316L)

Remarks

Pack quantity	1 pcs.
---------------	--------

E11296



Male cordsets


ASTGH030VAS0001A03

Electrical connection

Cable: 1 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L)

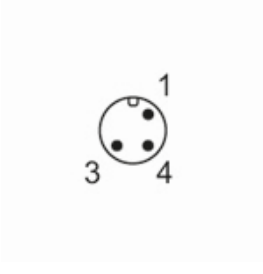

Connection

1	BN
3	BU
4	BK

BK = Core colors :
BN = black
BU = brown
 blue