


E11316



Patchcords with valve plug

AVDAA031--S0010A03

Article no longer available - archive entry

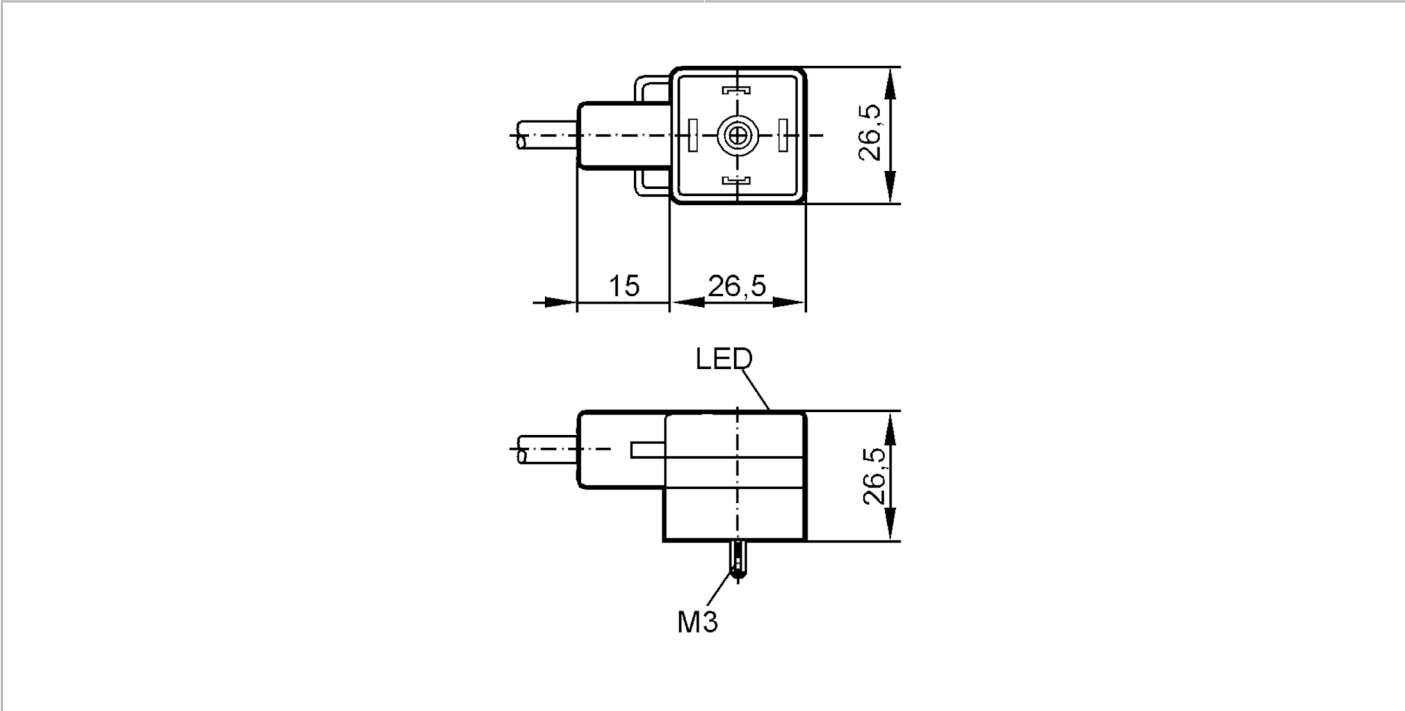

Electrical data		
Operating voltage	[V]	< 24 AC/DC
Overvoltage protection		yes; (VDR)
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Material		PUR
Molded-body material		PUR
Displays / operating elements		
Display	Switching status	1 x LED, yellow
Accessories		
Items supplied	screw	
	panel for labelling	
Remarks		
Pack quantity	1 pcs.	

E11316



Patchcords with valve plug

AVDAA031--S0010A03

Electrical connection

Cable: 10 m, PUR / PVC; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Electrical connection - Socket

Connector: 1 x valve type A DIN, angled; Moulded body: PUR



Connection



BN = Core colors :
brown
BU = blue
GN/YE = green/yellow