

E11318




Connection cable

VDOGF030MSS0005B03STGF030MSS

Article no longer available - archive entry

Alternative articles: E11353  
When selecting an alternative article and accessories please note that technical data may differ!

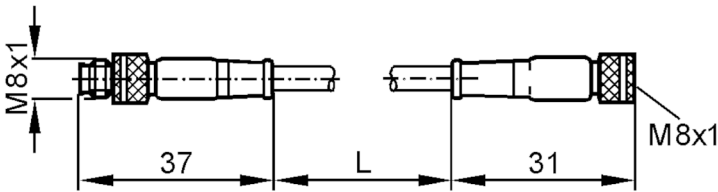

| Electrical data      |      |                      |
|----------------------|------|----------------------|
| Operating voltage    | [V]  | 10...30 DC           |
| Protection class     |      | III                  |
| Operating conditions |      |                      |
| Ambient temperature  | [°C] | -25...90             |
| Protection           |      | IP 68                |
| Mechanical data      |      |                      |
| Material             |      | TPU (urethane)       |
| Molded-body material |      | TPU (urethane)       |
| Material nut         |      | brass, nickel-plated |
| Remarks              |      |                      |
| Pack quantity        |      | 1 pcs.               |

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.6...0.7 Nm



# E11318




## Connection cable

VDOGF030MSS0005B03STGF030MSS

### Electrical connection

Cable: 5 m, TPU (urethane), black, Ø 4.5 mm; 3 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection

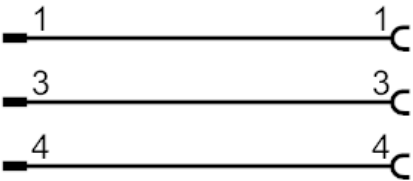

### Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.6...0.7 Nm

