

E11346




Connection cable

VDOAH032MSS00,3H03STGF030MSS

Article no longer available - archive entry

Alternative articles: EVC250
When selecting an alternative article and accessories please note that technical data may differ!

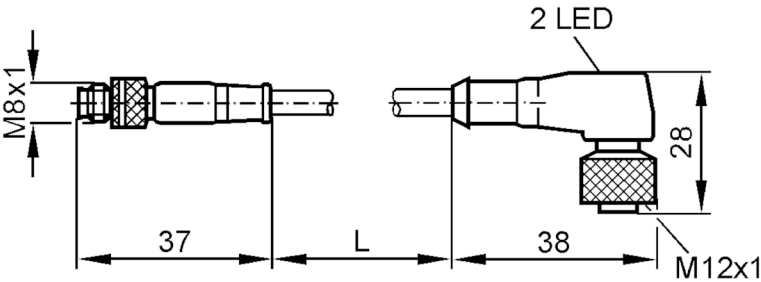

Application		
System	Free from silicone; Halogen-free; gold-plated contacts	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		III
Max. current load total	[A]	3
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 68
Mechanical data		
Material		PUR
Molded-body material		PUR
Material nut		brass, nickel-plated
Displays / operating elements		
Display	Switching status	1 x LED, yellow
	Power	1 x LED, green

E11346



Connection cable

 
VDOAH032MSS00,3H03STGF030MSS

Remarks

Pack quantity 1 pcs.

Electrical connection - plug


Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Connection

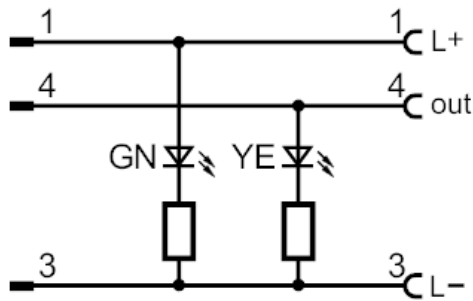

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

