

# E11362




## Connection cable

VDOAF040MSS00,3H04STGF040MSS

Article no longer available - archive entry

Alternative articles: EVC300  
When selecting an alternative article and accessories please note that technical data may differ!

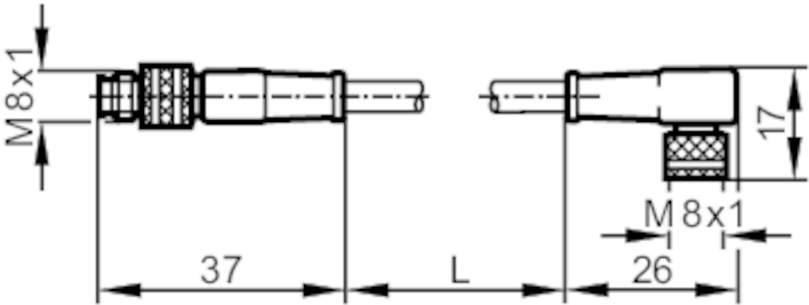

| Application                 |                                                        |
|-----------------------------|--------------------------------------------------------|
| System                      | Free from silicone; Halogen-free; gold-plated contacts |
| Free from silicone          | yes                                                    |
| Electrical data             |                                                        |
| Operating voltage [V]       | < 60 AC / < 75 DC                                      |
| Protection class            | III                                                    |
| Max. current load total [A] | 3                                                      |
| Operating conditions        |                                                        |
| Ambient temperature [°C]    | -25...80                                               |
| Protection                  | IP 68                                                  |
| Mechanical data             |                                                        |
| Material                    | PUR                                                    |
| Molded-body material        | PUR                                                    |
| Material nut                | brass, nickel-plated                                   |
| Remarks                     |                                                        |
| Pack quantity               | 1 pcs.                                                 |

# E11362



## Connection cable

VDOAF040MSS00,3H04STGF040MSS

### Electrical connection - plug


Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



### Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 4.4 mm; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

#### Connection

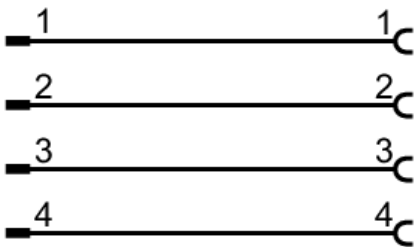

### Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

