




## Connection cable

VDOGH040MSS0005H04STGF040MSS

Article no longer available - archive entry

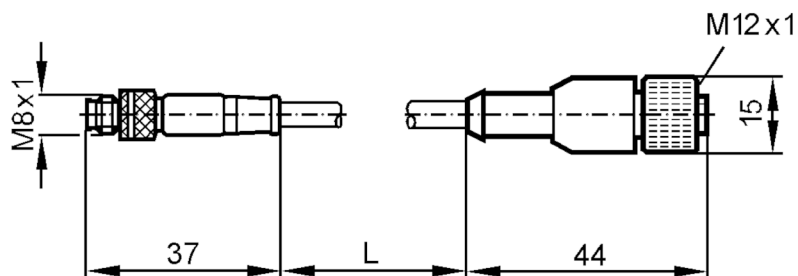

| Application                 |                                                        |
|-----------------------------|--------------------------------------------------------|
| System                      | Free from silicone; Halogen-free; gold-plated contacts |
| Free from silicone          | yes                                                    |
| Electrical data             |                                                        |
| Operating voltage [V]       | < 60 AC / < 75 DC                                      |
| Protection class            | III                                                    |
| Max. current load total [A] | 3                                                      |
| Operating conditions        |                                                        |
| Ambient temperature [°C]    | -25...85                                               |
| Protection                  | IP 68                                                  |
| Mechanical data             |                                                        |
| Material                    | PUR                                                    |
| Molded-body material        | PUR                                                    |
| Material nut                | brass, nickel-plated                                   |
| Remarks                     |                                                        |
| Pack quantity               | 1 pcs.                                                 |



## Connection cable

VDOGH040MSS0005H04STGF040MSS

### Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



### Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 5 mm; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

#### Connection



### Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

