


E12422



Ethernet connection cable

VSTGN040ZDS00,5L04STGN040ZDS

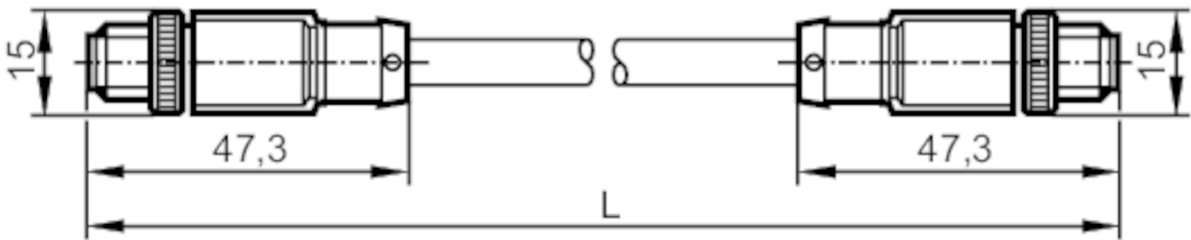

Application		
System		gold-plated contacts; screened cable
Design		Ethernet cable, D-coded
Electrical data		
Operating voltage	[V]	< 50 AC / < 60 DC
Protection class		III
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-20...90
Protection		IP 67
Mechanical data		
Weight	[g]	66.1
Dimensions	[mm]	15 x 15 x 47.3
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.

E12422



Ethernet connection cable

VSTGN040ZDS00,5L04STGN040ZDS

Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Moulded body: TPU (urethane); Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: shield connected



Electrical connection

Cable: 0.5 m, PVC, green, screened; 4 x 0.34 mm²

Connection



Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Moulded body: TPU (urethane); Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: shield connected

