


E12430



Female cordset


ADOGD040ZDS0002H04

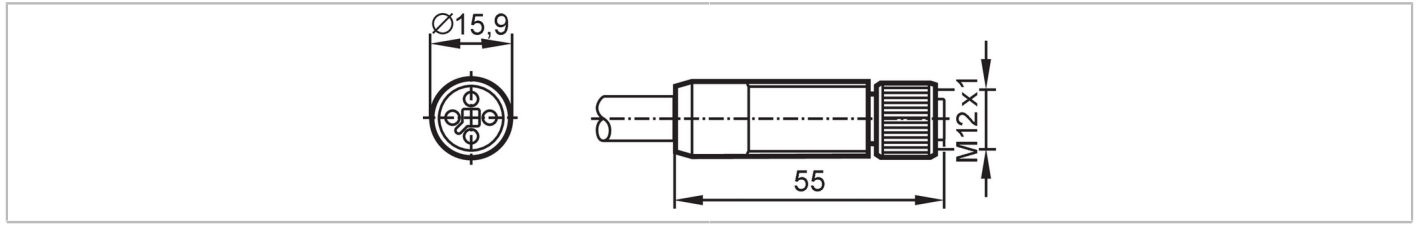

| Application | | |
|-------------------------|------|-----------------------------|
| Special feature | | gold-plated contacts |
| Design | | Power cable, T-coded |
| Application | | Industrial applications |
| Electrical data | | |
| Operating voltage | [V] | < 60 DC |
| Max. current load total | [A] | 12 |
| Operating conditions | | |
| Ambient temperature | [°C] | -25...85 |
| Protection | | IP 67 |
| Mechanical data | | |
| Weight | [g] | 242.7 |
| Dimensions | [mm] | 15.4 x 15.4 x 52.8 |
| Material | | PP |
| Molded-body material | | TPU (urethane) |
| Material nut | | diecast zinc, nickel-plated |
| Remarks | | |
| Pack quantity | | 1 pcs. |

| Electrical connection | |
|---|--|
| Cable: 2 m, PUR, black, Ø 8 mm; 4 x 1.5 mm ² | |

 Electrical connection - Socket
Connector: 1 x M12, straight; coding: T; Contacts: 4, gold-plated; Moulded body: TPU (urethane); Locking: diecast zinc, nickel-plated




E12430



Female cordset

ADOGD040ZDS0002H04

Connection

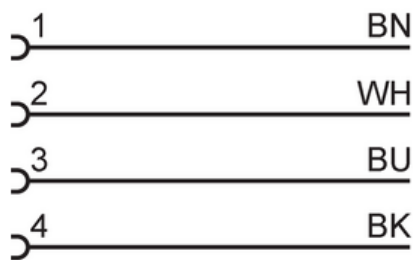

Core colors :
BK = black
BN = brown
BU = blue
WH = white