


E12430



Female cordset


ADOGD040ZDS0002H04

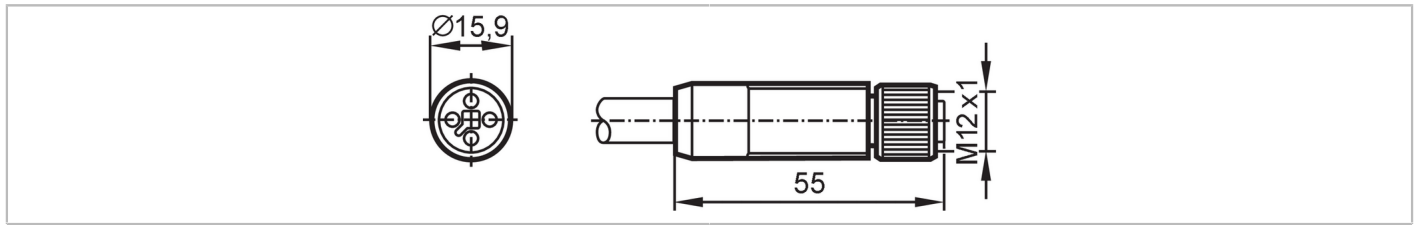

Application	
Special feature	gold-plated contacts
Design	Power cable, T-coded
Application	Industrial applications
Electrical data	
Operating voltage [V]	< 60 DC
Max. current load total [A]	12
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 67
Mechanical data	
Weight [g]	242.7
Dimensions [mm]	15.4 x 15.4 x 52.8
Material	PP
Molded-body material	TPU (urethane)
Material nut	diecast zinc, nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection
Cable: 2 m, PUR, black, Ø 8 mm; 4 x 1.5 mm²

 Electrical connection - Socket
Connector: 1 x M12, straight; coding: T; Moulded body: TPU (urethane); Locking: diecast zinc, nickel-plated; Contacts: gold-plated




E12430



Female cordset

ADOGD040ZDS0002H04

Connection

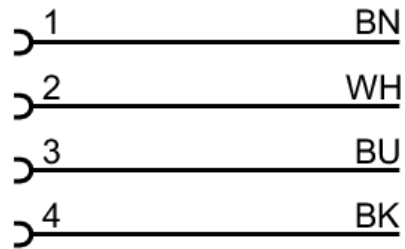

Core colors :

BK =	black
BN =	brown
BU =	blue
WH =	white