


E12459



Connection cable

ADOGH050MSS00,3K05STGK120MSS

Article no longer available - archive entry

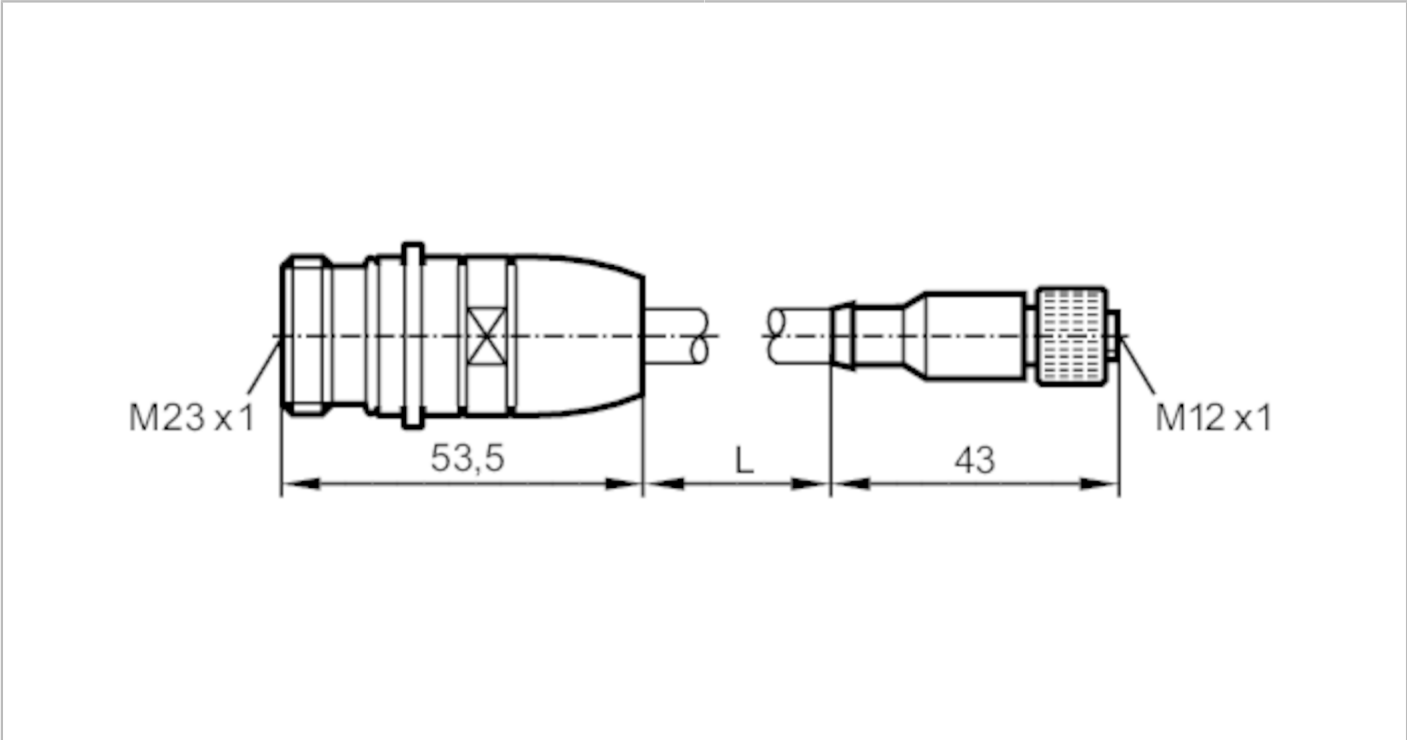

Application	
System	gold-plated contacts; screened cable
Electrical data	
Operating voltage [V]	< 30 AC / < 36 DC
Operating conditions	
Ambient temperature [°C]	-20...90
Protection	IP 67
Mechanical data	
Weight [g]	110.1
Molded-body material	brass, nickel-plated / TPU (urethane)
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

E12459




Connection cable

ADOGH050MSS00,3K05STGK120MSS

Electrical connection - plug


Connector: 1 x M23, straight; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated; Contacts: gold-plated; Shielded connection cable: shield connected

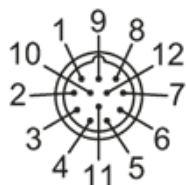

Electrical connection

Cable: 0.3 m, PUR, black, Ø 4.8 mm, screened; 5 x 0.25 mm²

Connection

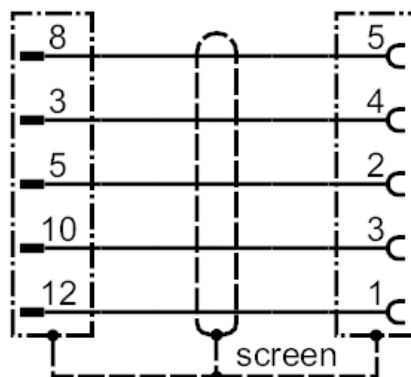

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane), black; Locking: brass, nickel-plated; Contacts: gold-plated; Shielded connection cable: shield connected

