


E12464



Female wirable connectors

SDOGF040MSSFKPG

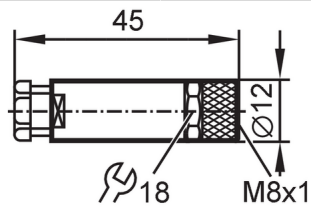

Application	
Special feature	gold-plated contacts
Application	Industrial applications
Electrical data	
Operating voltage [V]	< 30 AC/DC
Outputs	
Electrical design	PNP
Operating conditions	
Ambient temperature [°C]	-40...85
Protection	IP 67
Mechanical data	
Weight [g]	11.2
Dimensions [mm]	12 x 12 x 45
Molded-body material	PBT / PA
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection
 screw terminals: 0.14...0.5 mm²; Cable sheath: Ø 3.5...5 mm

Electrical connection - Socket
 Connector: 1 x M8, straight; coding: A; Contacts: 4, gold-plated; Moulded body: PBT / PA; Locking: brass, nickel-plated

