


# E12489



## Y/T splitter

ZDO2H040MSS0000-00STGH040MSS

Article no longer available - archive entry

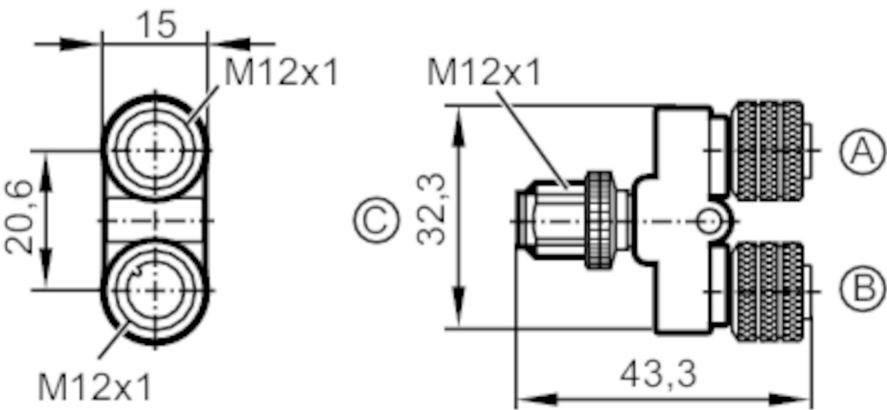

| Application                       |      |                                          |
|-----------------------------------|------|------------------------------------------|
| System                            |      | Free from silicone; gold-plated contacts |
| Free from silicone                |      | yes                                      |
| Electrical data                   |      |                                          |
| Operating voltage                 | [V]  | < 60 AC/DC                               |
| Max. current load per module/slot | [A]  | 12                                       |
| Max. current load total           | [A]  | 12; (...40 °C)                           |
| Operating conditions              |      |                                          |
| Ambient temperature               | [°C] | -25...70                                 |
| Protection                        |      | IP 67                                    |
| Mechanical data                   |      |                                          |
| Weight                            | [g]  | 24.6                                     |
| Material                          |      | TPU (urethane)                           |
| Molded-body material              |      | TPU (urethane)                           |
| Material nut                      |      | diecast zinc                             |
| Connector type                    |      | M12                                      |
| Remarks                           |      |                                          |
| Pack quantity                     |      | 1 pcs.                                   |




## Y/T splitter

ZDO2H040MSS0000-00STGH040MSS

## Electrical connection

## Connection

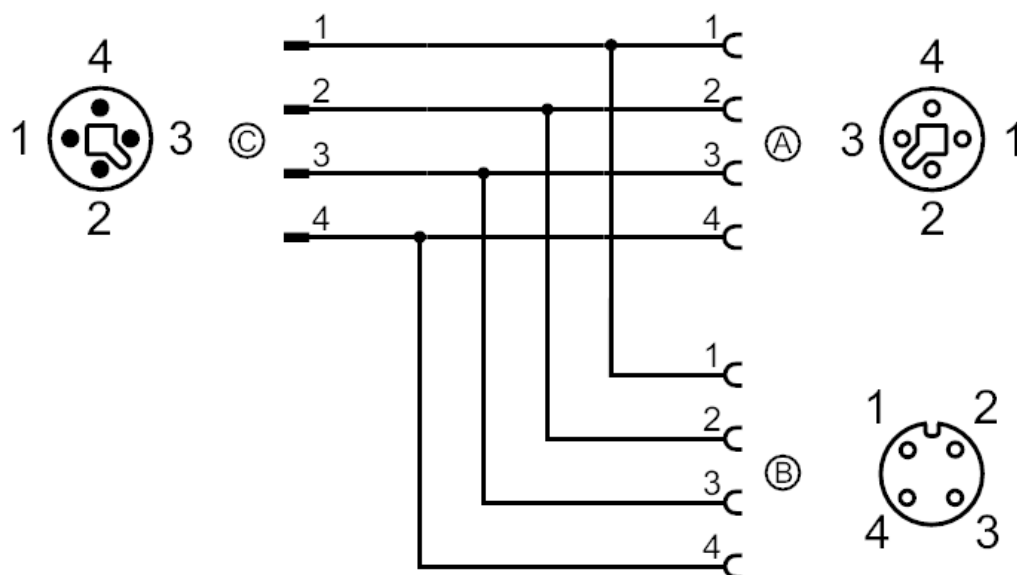

## Electrical connection - Socket

Connector: 2 x M12; Moulded body: TPU (urethane); Locking: diecast zinc; Contacts: gold-plated

## Electrical connection - plug

Connector: 1 x M12; Moulded body: TPU (urethane); Locking: diecast zinc; Contacts: gold-plated