


E12490



Ethernet connection cable

VSTGN040ZDS00,5L04STGP080--S

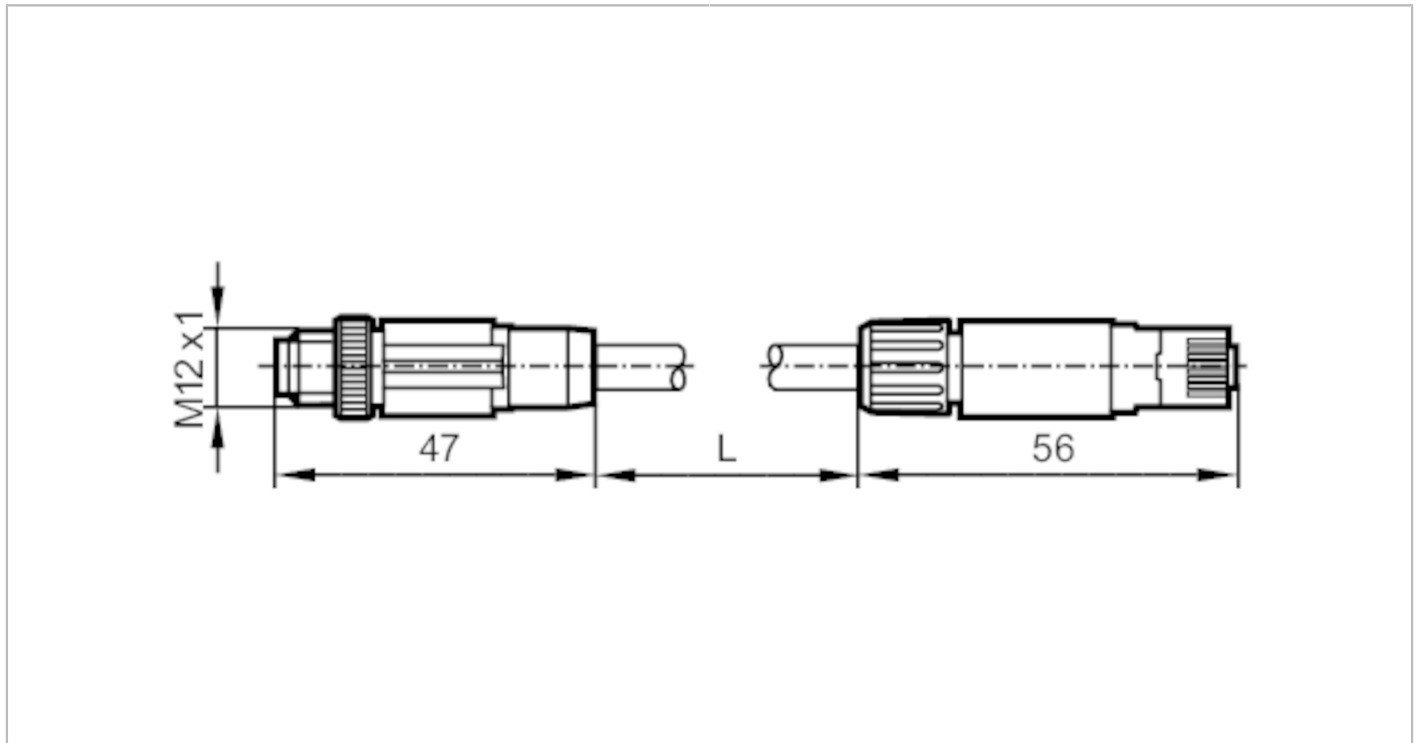

Application	
System	screened cable
Design	Ethernet cable, D-coded
Application	Cross-over patch cable; Patch cable
Operating conditions	
Ambient temperature [°C]	-25...70
Protection	IP 67; IP 20; (M12 plug / RJ45 plug)
Mechanical data	
Weight [g]	73.1
Material	TPU / PA
Molded-body material	PA / TPU (urethane)
Material nut	diecast zinc, nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection - plug M12

Connector: 1 x M12, straight; Moulded body: PA; Locking: diecast zinc, nickel-plated; Tightening torque: 0.7...0.9 Nm



E12490




Ethernet connection cable

VSTGN040ZDS00,5L04STGP080--S

Electrical connection

Cable: 0.5 m, PVC, green, \varnothing 6.5 mm, screened; 2 x 2 x 0.38 mm²

Connection

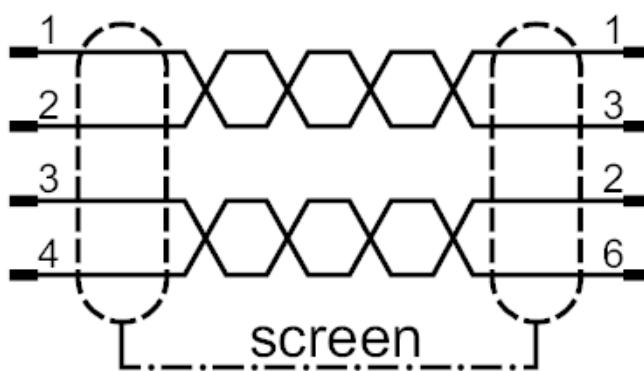

Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Moulded body: TPU (urethane)

