


E12495



Female cordset


ADOGD040ZDS0005H04

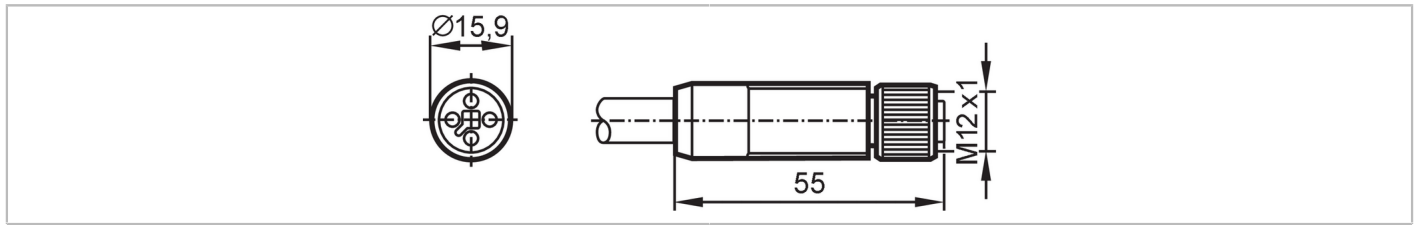

Application		
Special feature		gold-plated contacts
Design		Power cable, T-coded
Application		Industrial applications
Electrical data		
Operating voltage	[V]	< 60 DC
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 67
Mechanical data		
Weight	[g]	545
Dimensions	[mm]	15.4 x 15.4 x 52.8
Material		PP
Molded-body material		TPU (urethane)
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection
Cable: 5 m, PUR, black, Ø 8 mm; 4 x 1.5 mm²

 Electrical connection - Socket
Connector: 1 x M12, straight; coding: T; Moulded body: TPU (urethane); Locking: diecast zinc, nickel-plated; Contacts: gold-plated




E12495



Female cordset

ADOGD040ZDS0005H04

Connection

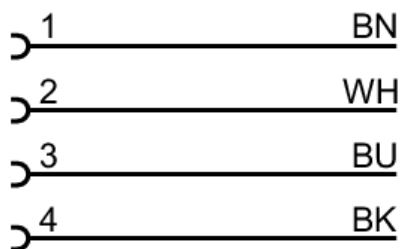

Core colors :
BK = black
BN = brown
BU = blue
WH = white