


E12499



Female wirable connectors

SDOGD040ZDSFKP

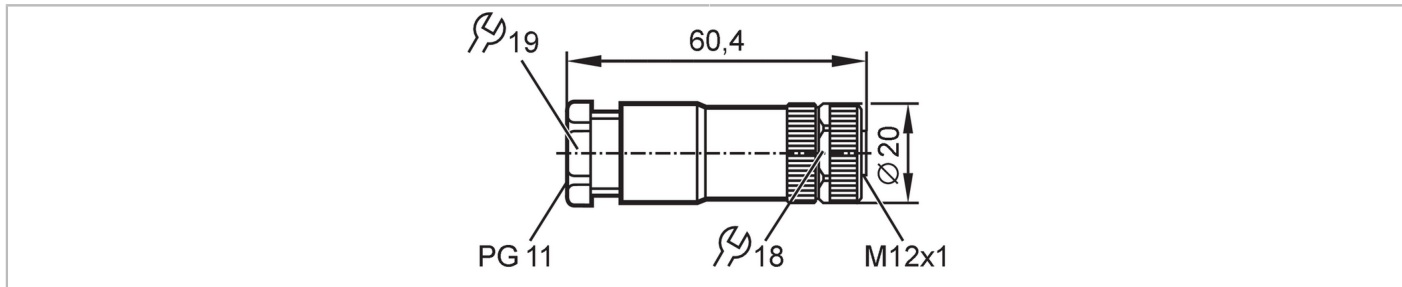

Application

| | |
|--------------------|--|
| Special feature | Free from silicone; gold-plated contacts |
| Design | Power cable, T-coded |
| Application | Industrial applications |
| Free from silicone | yes |

Electrical data

| | |
|-----------------------------|---|
| Operating voltage [V] | < 60 DC |
| Max. current load total [A] | 12; (when using conductors with 1.5 mm ²) |

Operating conditions

| | |
|--------------------------|----------|
| Ambient temperature [°C] | -40...85 |
| Protection | IP 67 |

Mechanical data

| | |
|----------------------|--------------|
| Weight [g] | 29 |
| Molded-body material | PA |
| Material nut | diecast zinc |
| Sealing material | NBR |

Remarks


| | |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

Electrical connection

screw terminals: 0.75...1.5 mm²; Cable sheath: Ø 8...10 mm

Electrical connection - Socket

 Connector: 1 x M12, straight; coding: T; Contacts: 4, gold-plated; Moulded body: PA; Locking: diecast zinc; sealing: NBR; Tightening torque: 0.4 Nm



Connection

