


# E12511



## Male cordsets

ASTGN040ZDS0005L04

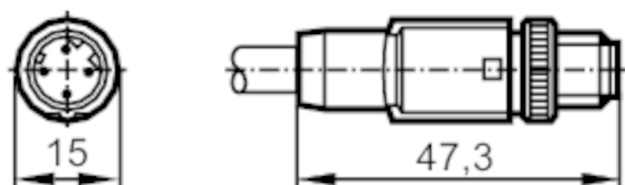

### Application

|        |                         |
|--------|-------------------------|
| System | gold-plated contacts    |
| Design | Ethernet cable, D-coded |

### Electrical data

|                         |     |             |
|-------------------------|-----|-------------|
| Operating voltage       | [V] | < 250 AC/DC |
| Max. current load total | [A] | 4           |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -40...70 |
| Protection          |      | IP 67    |

### Mechanical data

|                      |      |                             |
|----------------------|------|-----------------------------|
| Weight               | [g]  | 349.2                       |
| Dimensions           | [mm] | 15 x 15 x 47.3              |
| Material             |      | TPU (urethane)              |
| Molded-body material |      | TPU (urethane)              |
| Material nut         |      | diecast zinc, nickel-plated |

### Remarks

|               |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |
|---------------|--|--------|

# E12511



## Male cordsets

ASTGN040ZDS0005L04

### Electrical connection


Cable: 5 m, PVC, green, Ø 6.5 mm; 4 x 0.34 mm<sup>2</sup>

### Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Moulded body: TPU (urethane); Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: shield connected



### Connection

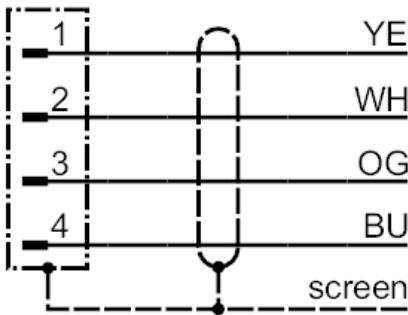

Core colors :  
BU = blue  
OG = orange  
WH = white  
YE = yellow