


E12513



Male cordsets

ASTGN040ZDS0020L04

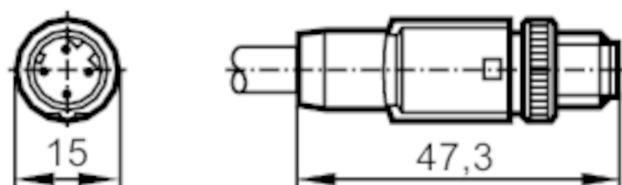

Application

System	gold-plated contacts
Design	Ethernet cable, D-coded

Electrical data

Operating voltage	[V]	< 250 AC/DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-40...70
Protection		IP 67

Mechanical data

Weight	[g]	1380.5
Dimensions	[mm]	15 x 15 x 47.3
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		diecast zinc, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E12513



Male cordsets

ASTGN040ZDS0020L04

Electrical connection


Cable: 20 m, PVC, green, Ø 6.5 mm; 4 x 0.34 mm²

Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Moulded body: TPU (urethane); Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: shield connected



Connection

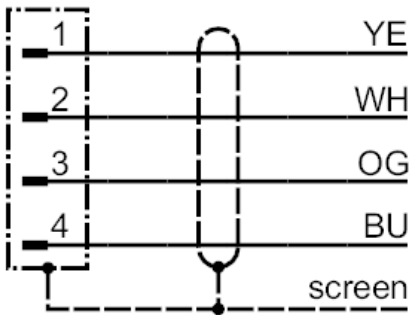

BU =	Core colors :
OG =	blue
WH =	orange
YE =	white
	yellow