


E12524



Mounting brackets for manual valves and ball valves

MOUNTING KIT FOR MANUAL VALVES F10/M8

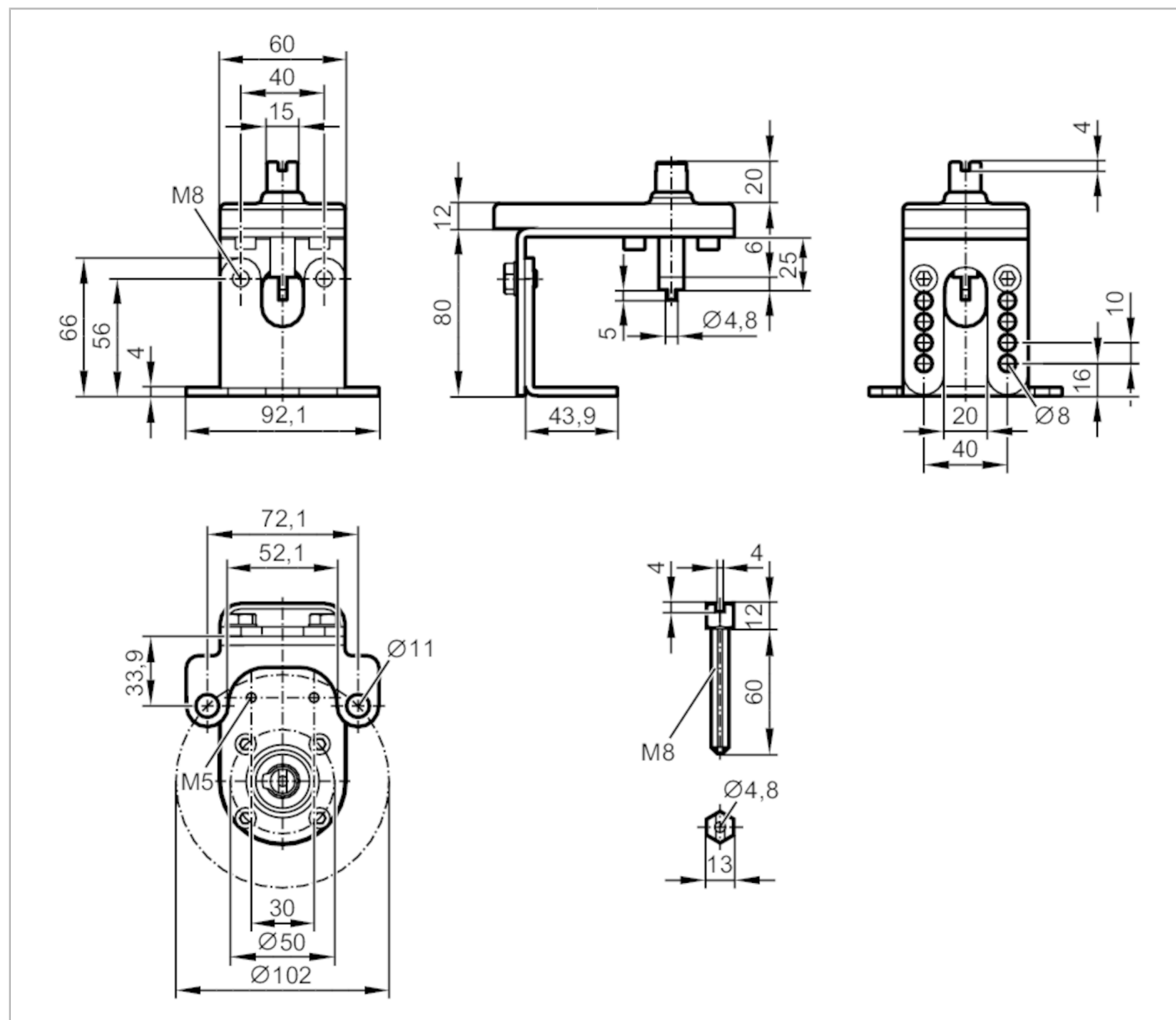

Operating conditions

Ambient temperature	[°C]	-30...80
---------------------	------	----------

Mechanical data

Weight	[g]	602.5
Top flange diameter	[mm]	102
ISO top flange type		F10
Shaft extension		M8
Material	Mounting plate: plastics; metal parts: stainless steel (1.4301 / 304)	

Remarks

Pack quantity	1 pcs.
---------------	--------