


E12540



Damping magnet

MAGNET M7.0 NEODYM, SCREW M6

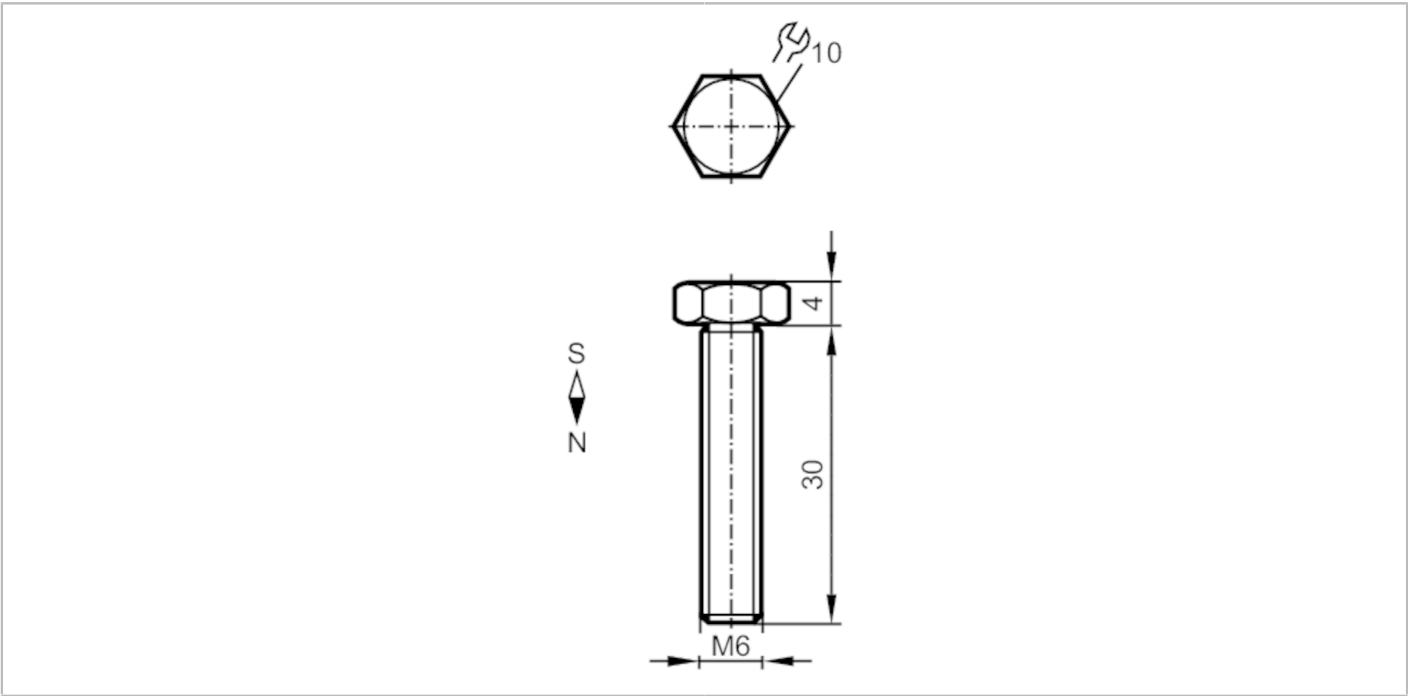

Operating conditions		
Ambient temperature	[°C]	-40...80
Mechanical data		
Weight	[g]	8.9
Dimensions	[mm]	M6 / L = 33.5
Thread designation		M6
Material		neodymium galvanized
Magnetic field strength	[mT]	220
Remarks		
Pack quantity		1 pcs.