


# E12565



## Connecting cordset with AMP connector

ADOGX060--A002E06

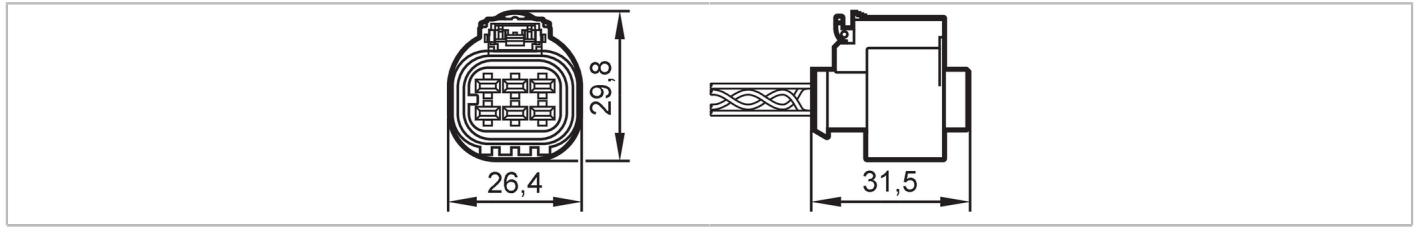

Application	
Application	for mobile applications
Electrical data	
Operating voltage [V]	12...24 DC
Operating conditions	
Ambient temperature [°C]	-40...100
Ambient temperature (moving) [°C]	-40...100
Protection	IP 67; (mating connector plugged in)
Mechanical data	
Weight [g]	246.4
Molded-body material	PBT
Remarks	
Pack quantity	1 pcs.

**Electrical connection**  
Cable: 2 m, PVC; 4 x 2.5 mm<sup>2</sup> + 2 x 0.5 mm<sup>2</sup>

**Electrical connection - Socket**

Connector: 1 x AMP connector, straight; Contacts: 6, nickel-plated; Moulded body: PBT




# E12565



## Connecting cordset with AMP connector

ADOGX060--A002E06

### Connection

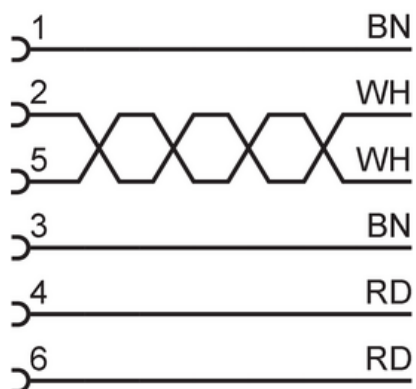

BN = brown  
RD = red  
WH = white

Core colors :