


E12572



Connection cable

VDOGH080MSS0001H04STGH040MSS

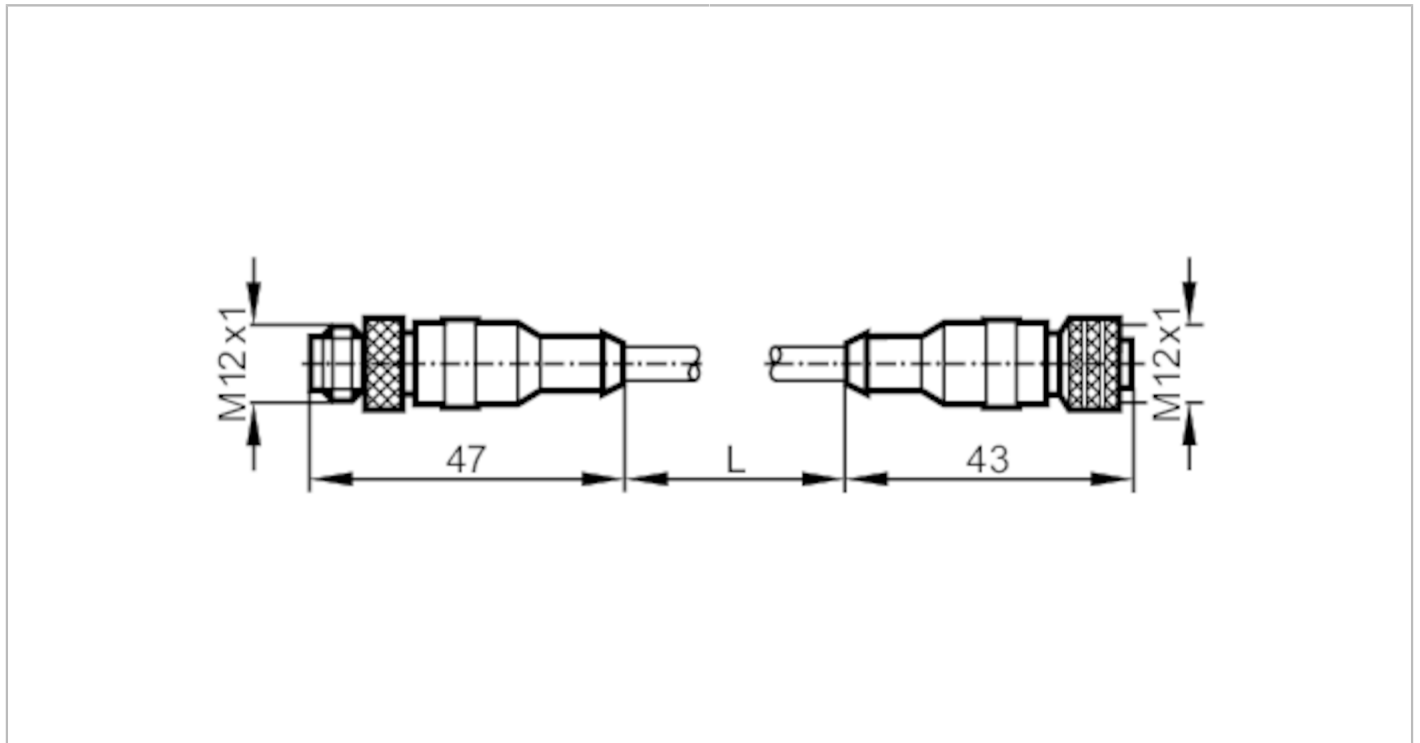

Application	
System	Halogen-free
Application	cable to connect a light tower DV15xx to an IO-Link master
Electrical data	
Operating voltage [V]	< 30 AC / < 36 DC
Operating conditions	
Ambient temperature [°C]	-25...80
Protection	IP 68
Mechanical data	
Weight [g]	51
Material	PUR
Material nut	brass, nickel-plated / brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm



E12572




Connection cable

VDOGH080MSS0001H04STGH040MSS

Electrical connection

Cable: 1 m, PUR, Halogen-free, black, Ø 6.8 mm; 3 x 0.25 mm²

Connection

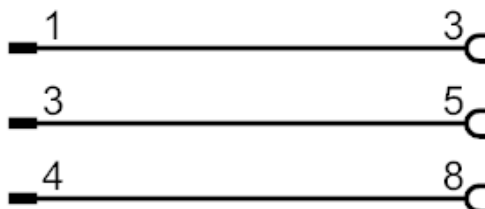

Electrical connection - Socket

Connector: 1 x M12, straight; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm

