


# E12582



## Wirable AMP socket

SDOGV060--AFKCR

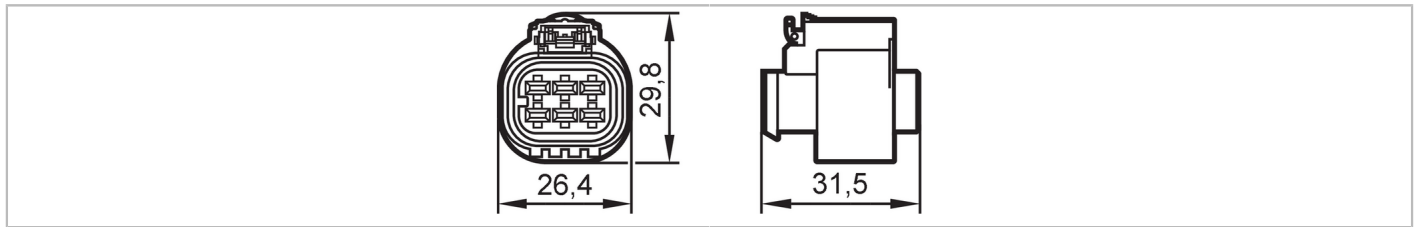

### Application

Application Use in mobile and harsh applications

### Electrical data

Operating voltage [V] 12...24 DC

### Operating conditions

Ambient temperature [°C] -40...100

Ambient temperature (moving) [°C] -40...100

Protection IP 67; (mating connector plugged in)

### Mechanical data

Weight [g] 14

Dimensions [mm] 29.8 x 26.4 x 31.5

Material socket housing: PBT; Contacts: tin-plated

### Accessories

Items supplied cover plug: 6

sealing of the individual cores: 2 x 0,5 mm<sup>2</sup>

sealing of the individual cores: 4 x 2,5 mm<sup>2</sup>

Crimp contacts: 6

### Remarks

Pack quantity 1 pcs.


### Electrical connection

terminals: 2 x 0.5 mm<sup>2</sup>

4 x 2.5 mm<sup>2</sup>

### Electrical connection - Socket

#### Connection

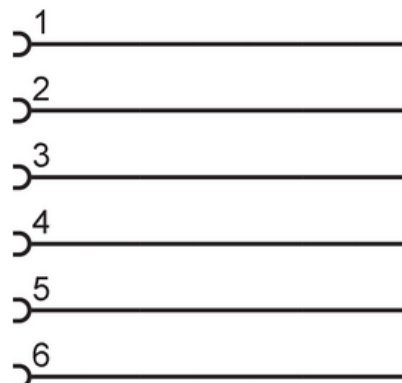

Connector: 1 x AMP connector, straight; Contacts: tin-plated