


# E12588



## Mounting brackets for manual valves and ball valves

MOUNTING KIT FOR MANUAL VALVES F03/M4

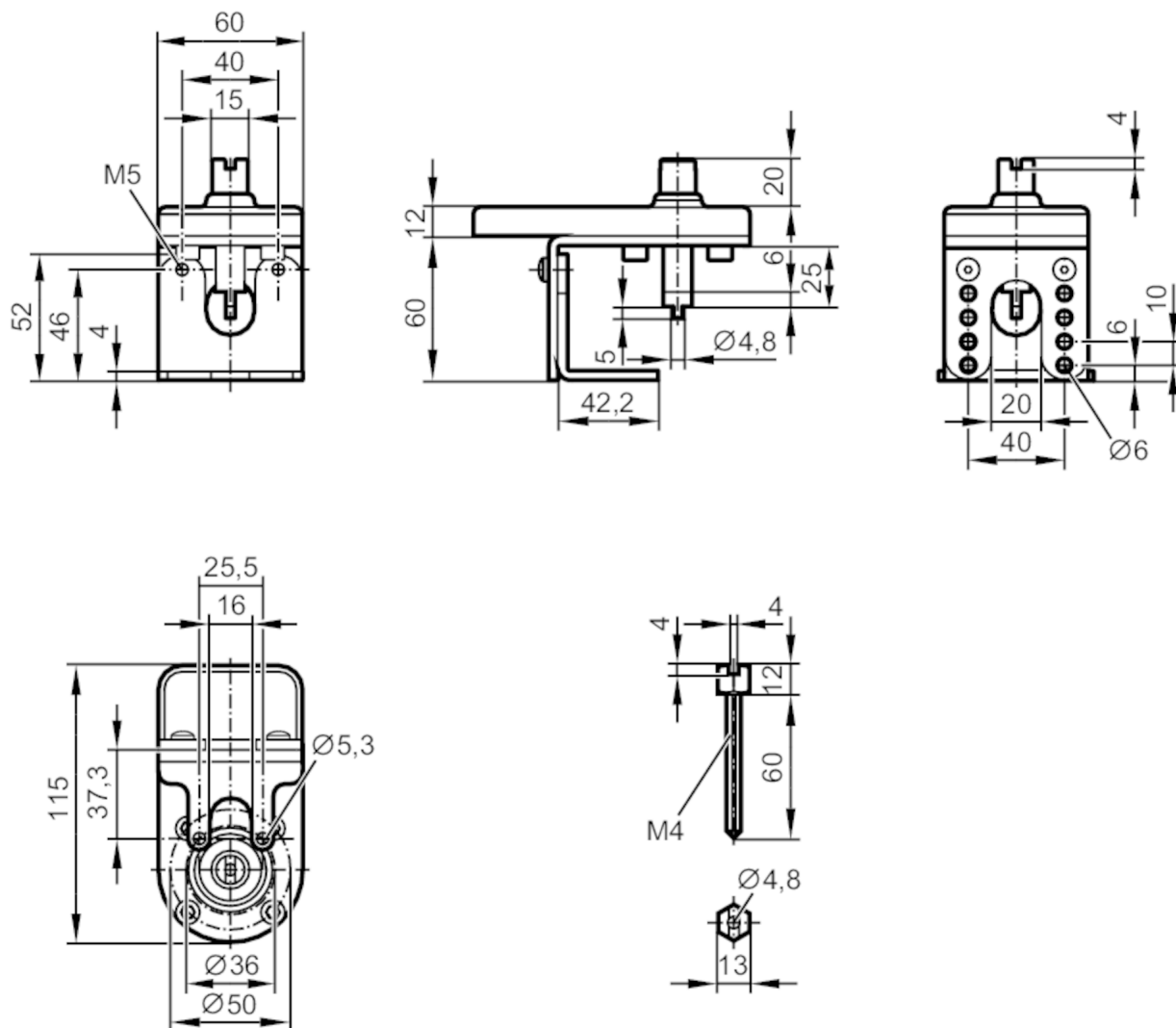

Application		
Design		for types IND, INE
Operating conditions		
Ambient temperature	[°C]	-30...80
Mechanical data		
Weight	[g]	459
Top flange diameter	[mm]	36
ISO top flange type		F03
Shaft extension		M4
Material	Mounting plate: plastics; metal parts: stainless steel (1.4301 / 304)	
Remarks		
Pack quantity		1 pcs.