


E12590



Mounting brackets for manual valves and ball valves

MOUNTING KIT FOR MANUAL VALVES F12/M10

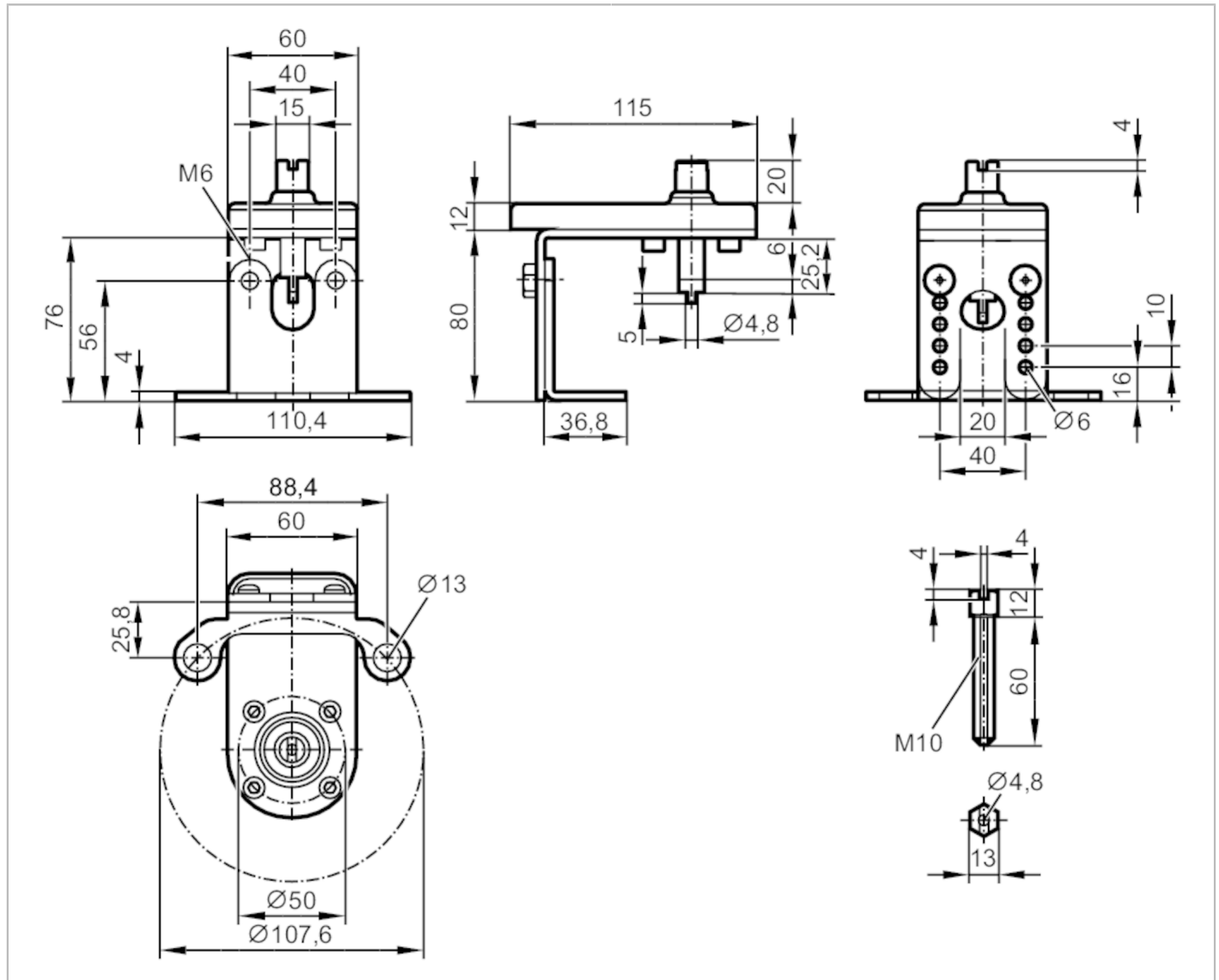

Application		
Design		for types IND, INE
Operating conditions		
Ambient temperature	[°C]	-30...80
Mechanical data		
Weight	[g]	592.5
Top flange diameter	[mm]	125
ISO top flange type		F12
Shaft extension		M10
Material		Mounting plate: plastics; metal parts: stainless steel (1.4301 / 304)
Remarks		
Pack quantity		1 pcs.