


# E12591



## Mounting brackets for manual valves and ball valves

MOUNTING KIT FOR MANUAL VALVES F14/M10

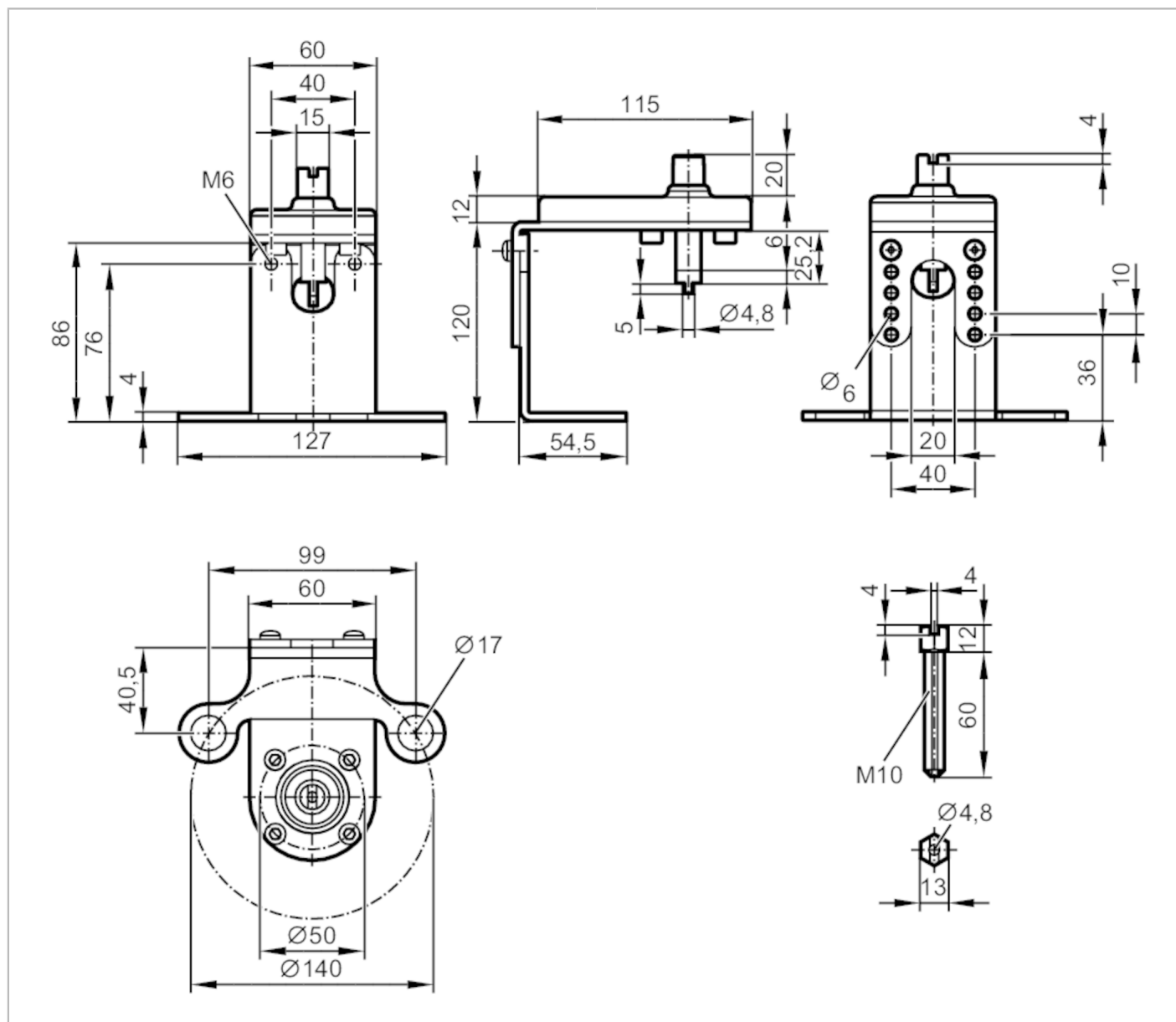

Application		
Design		for types IND, INE
Operating conditions		
Ambient temperature	[°C]	-30...80
Mechanical data		
Weight	[g]	719
Top flange diameter	[mm]	140
ISO top flange type		F14
Shaft extension		M10
Material	Mounting plate: plastics; metal parts: stainless steel (1.4301 / 304)	
Remarks		
Pack quantity	1 pcs.	