


E12613



Connection cable

ASTGH030MSS00,5H03

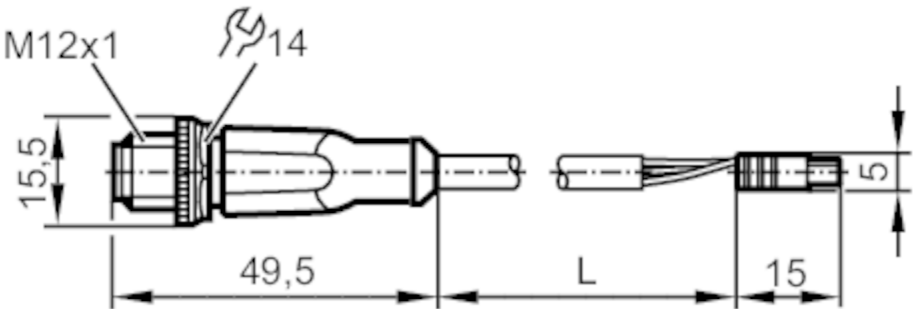

Application

System	Free from silicone; Halogen-free
Free from silicone	yes

Electrical data

Operating voltage [V]	< 50 AC/DC
Protection class	II
Max. current load total [A]	4

Operating conditions

Ambient temperature [°C]	-25...90
Ambient temperature (moving) [°C]	-25...90
Protection	IP 65

Mechanical data

Weight [g]	30.5
Material	housing: TPU (urethane) orange; knurled nut: nickel-plated brass
Tightening torque [Nm]	0.6...1.5

Remarks

Pack quantity	1 pcs.
---------------	--------

E12613



Connection cable

ASTGH030MSS00,5H03


Electrical connection



Electrical connection

Cable: 0.5 m, PUR, Halogen-free, black, Ø 4.9 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Connection

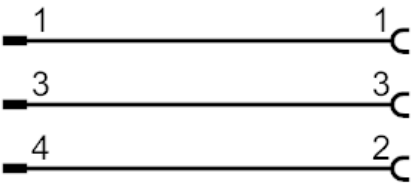

Electrical connection

