


# E12659



## Connection cable

VDOAX050MSS00,5H05STGH005MSS

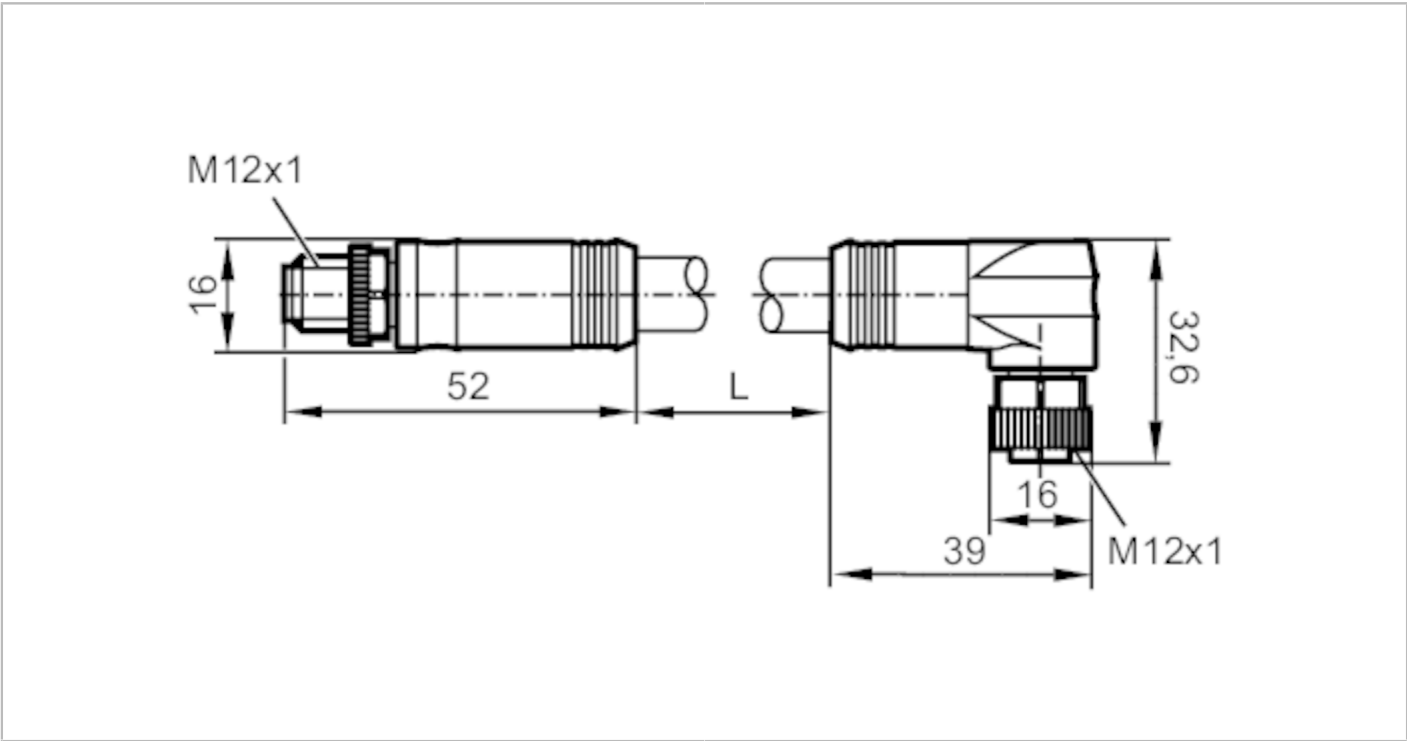

| Application             |      |                      |
|-------------------------|------|----------------------|
| System                  |      | gold-plated contacts |
| Design                  |      | Power cable, L-coded |
| Electrical data         |      |                      |
| Operating voltage       | [V]  | 64 DC                |
| Max. current load total | [A]  | 16                   |
| Operating conditions    |      |                      |
| Ambient temperature     | [°C] | -40...90             |
| Protection              |      | IP 67                |
| Mechanical data         |      |                      |
| Weight                  | [g]  | 151.9                |
| Material                |      | PP                   |
| Molded-body material    |      | TPE                  |
| Material nut            |      | brass, nickel-plated |
| Remarks                 |      |                      |
| Pack quantity           |      | 1 pcs.               |

# E12659



## Connection cable

VDOAX050MSS00,5H05STGH005MSS

### Electrical connection

Cable: 0.5 m, PUR, black, Ø 11.3 mm; 5 x 2.5 mm²


### Electrical connection - plug

Connector: 1 x M12, straight; coding: L; Moulded body: TPE; Locking: brass, nickel-plated; Contacts: gold-plated



### Electrical connection - 2

#### Connection

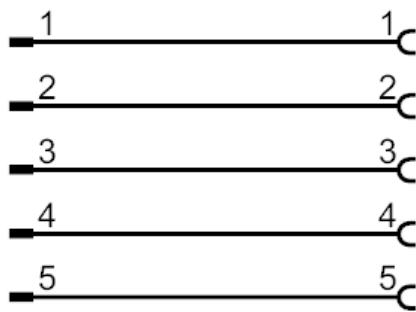

### Electrical connection - Socket

Connector: 1 x M12, angled; coding: L; Moulded body: TPE; Locking: brass, nickel-plated; Contacts: gold-plated

