


# E12672



## Female wirable connectors

SDOGX050ZDSFKPG

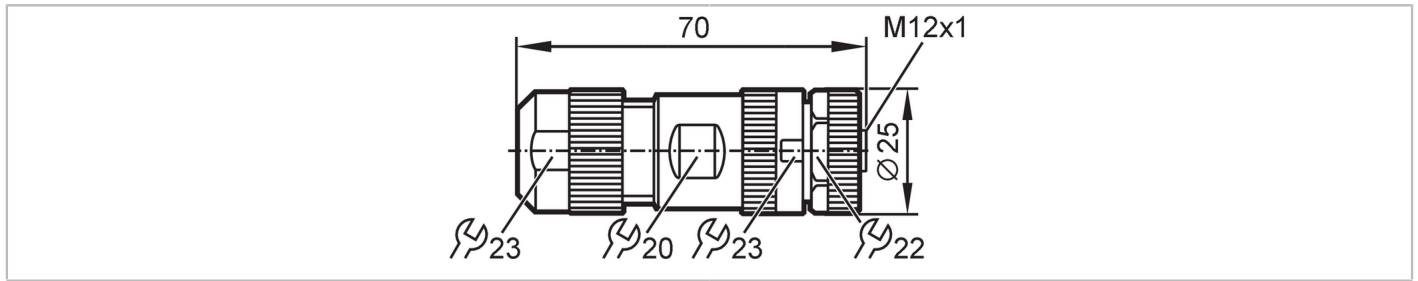

Application		
Special feature		gold-plated contacts
Design		L-coded
Application		Industrial applications
Electrical data		
Operating voltage	[V]	< 63 DC
Max. current load total	[A]	16
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Weight	[g]	53.2
Dimensions	[mm]	20 x 20 x 58
Molded-body material		PA
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
screw terminals: 1.5...2.5 mm <sup>2</sup> ; Cable sheath: Ø 8...13 mm; max. 1.5 with wire end ferrules		
Electrical connection - Socket		
Connector: 1 x M12, straight; coding: L; Contacts: 5, gold-plated; Moulded body: PA; Locking: diecast zinc, nickel-plated		

# E12672



## Female wirable connectors

SDOGX050ZDSFKPG

### Connection

AN\_i\_2045

Original Scale Drawing (MTD)



↓ 32% ↑ 312,5%

EPS Source  
Product Scale Drawing  
Frame Size: 36 mm x 26 mm

