


Y connection cable

YDOGS060--S0001H03DOGH030MSS

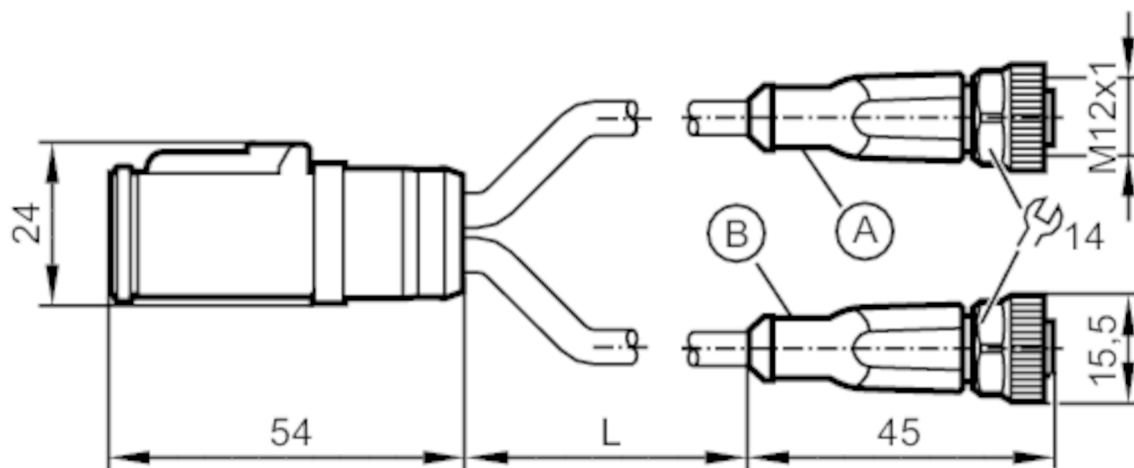

Application

System	Free from silicone; Halogen-free; Drag chain suitability
Free from silicone	yes

Electrical data

Operating voltage	[V]	8...32 DC
Protection class		III
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-40...80
Ambient temperature (moving)	[°C]	-20...80
Protection		IP 67; (mating connector plugged in)

Mechanical data

Weight	[g]	145.7
Material		PA; Socket: TPU (urethane) orange; sealing: FKM
Material nut		brass, nickel-plated
Number of ports splitter box		2
Drag chain suitability		yes
Drag chain suitability	Bending radius for flexible applications	min. 10 x cable diameter
	Travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s²
	Bending cycles	> 5 Mio.
	Torsional strain	± 180 °/m

Remarks

Pack quantity	1 pcs.
---------------	--------




Y connection cable

YDOGS060--S0001H03DOGH030MSS

Electrical connection - DEUTSCH connector C

Connection

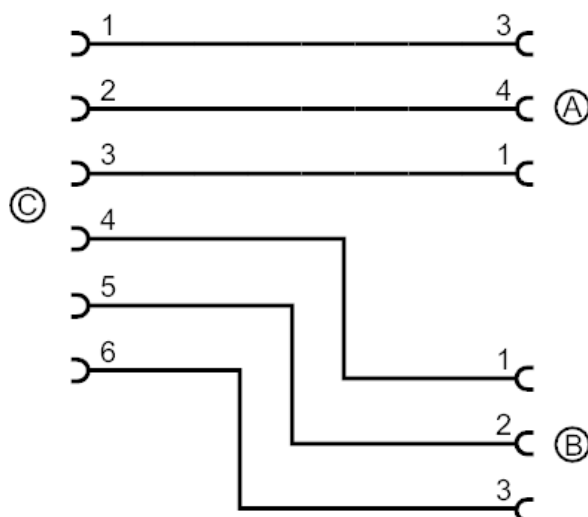


Connector: 1 x DEUTSCH connector, straight



Electrical connection - Socket A

Cable: 1 m, PUR, Halogen-free, black, Ø 5.4 mm; 3 x 0.50 mm² (28 x Ø 0.15 mm)

Connector: 1 x M12, straight; coding: A; Locking: brass, nickel-plated; Tightening torque: 0.6...1.5 Nm

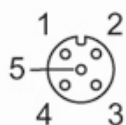

E12682



Y connection cable

YDOGS060--S0001H03DOGH030MSS

Electrical connection - Socket B

Cable: 1 m, PUR, Halogen-free, black, Ø 5.4 mm; 3 x 0.50 mm² (28 x Ø 0.15 mm)

Connector: 1 x M12, straight; coding: A; Locking: brass, nickel-plated; Tightening torque: 0.6...1.5 Nm

