


E12778



T-splitter

ZDO2B050ZDS0000-00STGB050ZDS

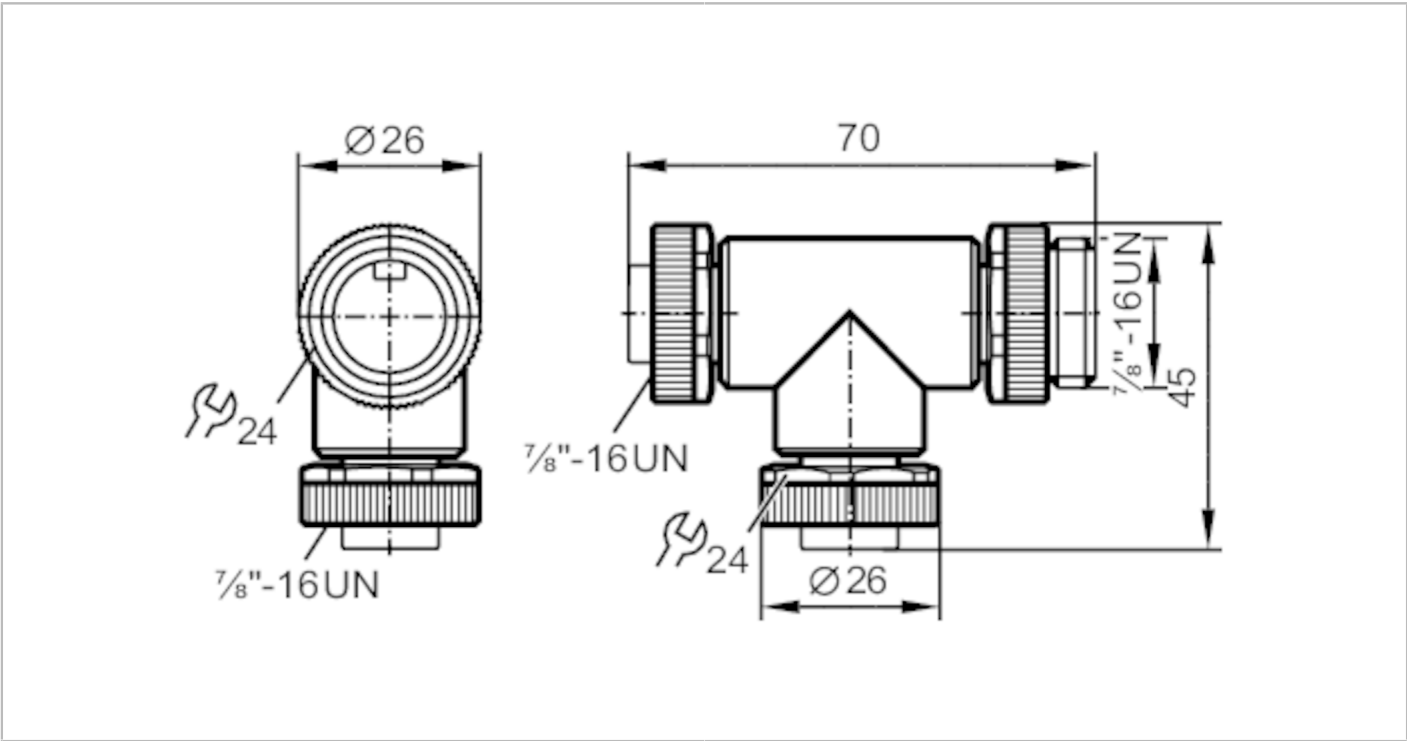

Application		
System		gold-plated contacts
Electrical data		
Operating voltage	[V]	< 400 AC/DC
Protection class		II
Max. current load total	[A]	8
Operating conditions		
Ambient temperature	[°C]	-30...85
Protection		IP 68
Mechanical data		
Weight	[g]	102.65
Material nut		diecast zinc
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug A		

Connector: 7/8"; Locking: diecast zinc; Contacts: gold-plated



E12778



T-splitter


ZDO2B050ZDS0000-00STGB050ZDS

Electrical connection

Connection

Electrical connection - Socket B

Connector: 7/8"; Locking: diecast zinc; Contacts: gold-plated

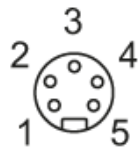

Electrical connection - Socket C

Connector: 7/8"; Locking: diecast zinc; Contacts: gold-plated

