


E12063



Patchcords with valve plug

STGH050MSS0006B03VDAA041--S

Article no longer available - archive entry

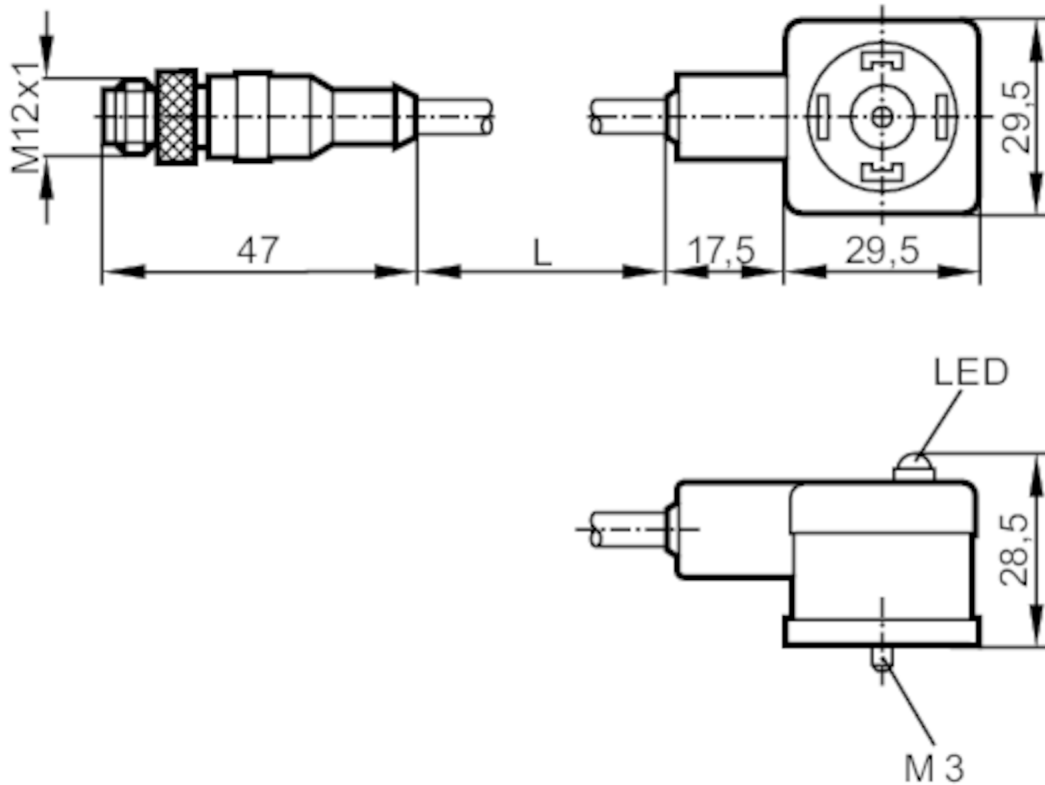

Application		
System	Free from silicone; Halogen-free; gold-plated contacts	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	< 24 AC/DC
Overvoltage protection	free-wheeling diode	
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection	IP 67	
Mechanical data		
Weight	[g]	44
Material	TPU (urethane)	
Molded-body material	TPU (urethane)	
Material nut	brass, nickel-plated	
Displays / operating elements		
Display	Power	1 x LED, green
Accessories		
Items supplied	screw	
	panel for labelling	

E12063



Patchcords with valve plug


STGH050MSS0006B03VDAA041--S

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Contacts: gold-plated

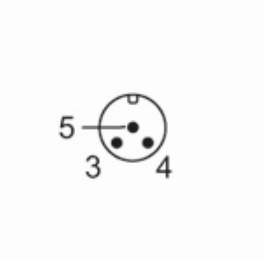

Electrical connection

Cable: 6 m, PUR / PVC, Halogen-free; 3 x 0.5 mm² (42 x Ø 0.1 mm)

Connection

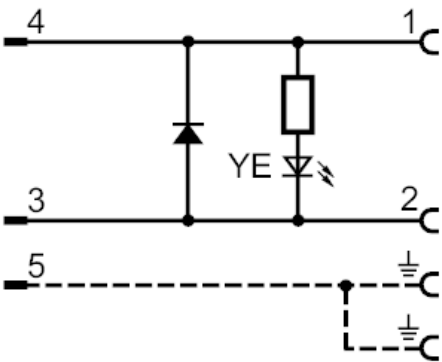

Electrical connection - Socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Contacts: nickel-plated brass

