


E12064



Patchcords with valve plug

STGH050MSS0008B03VDAA041--S

Article no longer available - archive entry

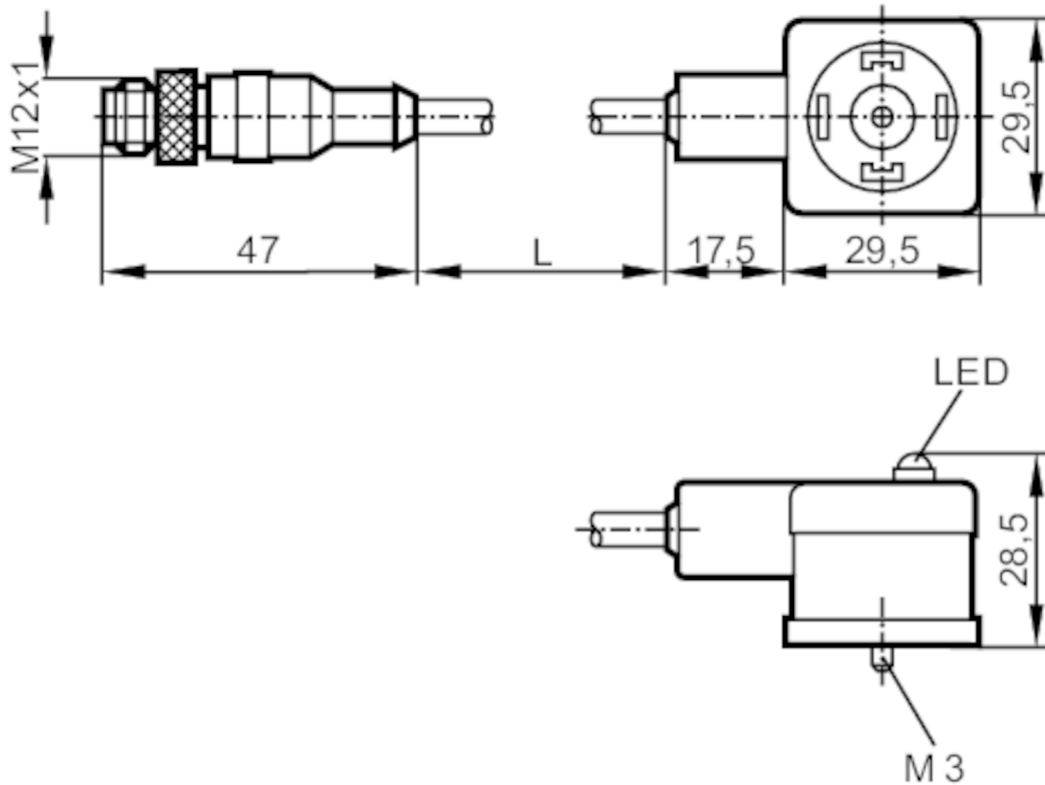

Application

System	Free from silicone; Halogen-free; gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 24 AC/DC
Overvoltage protection		free-wheeling diode

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	400
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated

Displays / operating elements

Display	Power	1 x LED, green
---------	-------	----------------

Accessories

Items supplied	screw
	panel for labelling

E12064



Patchcords with valve plug

 
STGH050MSS0008B03VDAA041--S

Remarks

Pack quantity 1 pcs.

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Contacts: gold-plated



Electrical connection

Cable: 8 m, PUR / PVC, Halogen-free; 3 x 0.5 mm² (42 x Ø 0.1 mm)

Connection

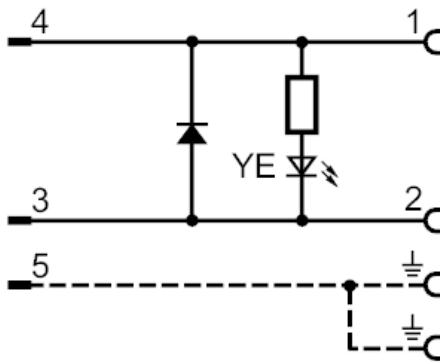

Electrical connection - Socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Contacts: nickel-plated brass

