


E12071



Wiring block

ZDO8H05HMSS0020B19

Article no longer available - archive entry

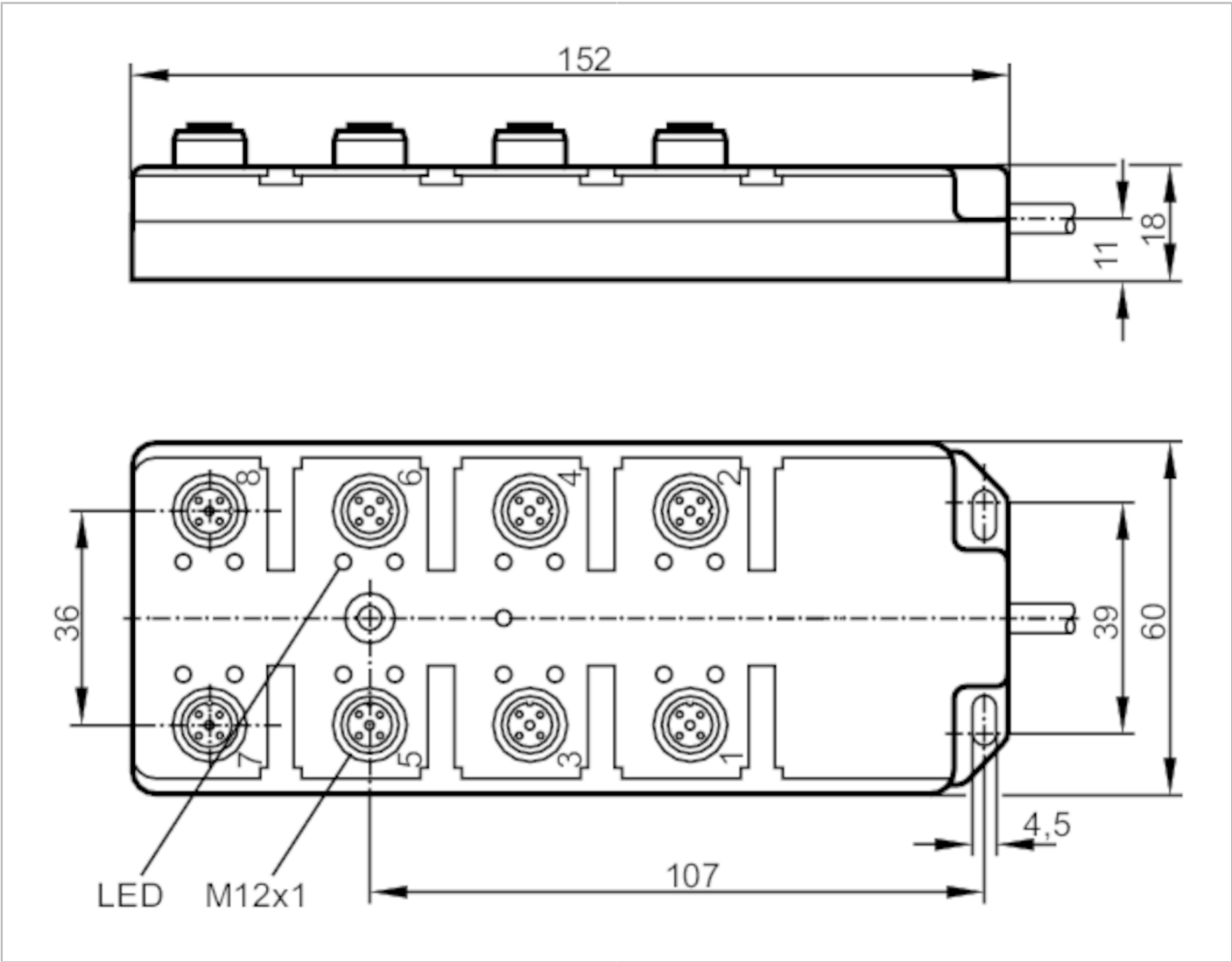

Application		
System	Free from silicone; Halogen-free; gold-plated contacts	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67

E12071



Wiring block

ZDO8H05HMSS0020B19

Mechanical data

Material	TPU (urethane)
Molded-body material	TPU (urethane)
Number of ports splitter box	8
Connector type	M12

Displays / operating elements

Display	Switching status	16 x LED, yellow
	Power	1 x LED, green

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 20 m, PUR, Halogen-free, black, Ø 11.6 mm; 16 x 0.5 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)

Electrical connection - slot

Connector: 8 x M12; coding: A; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm

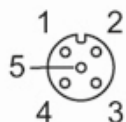


E12071



Wiring block

ZDO8H05HMSS0020B19

Connection

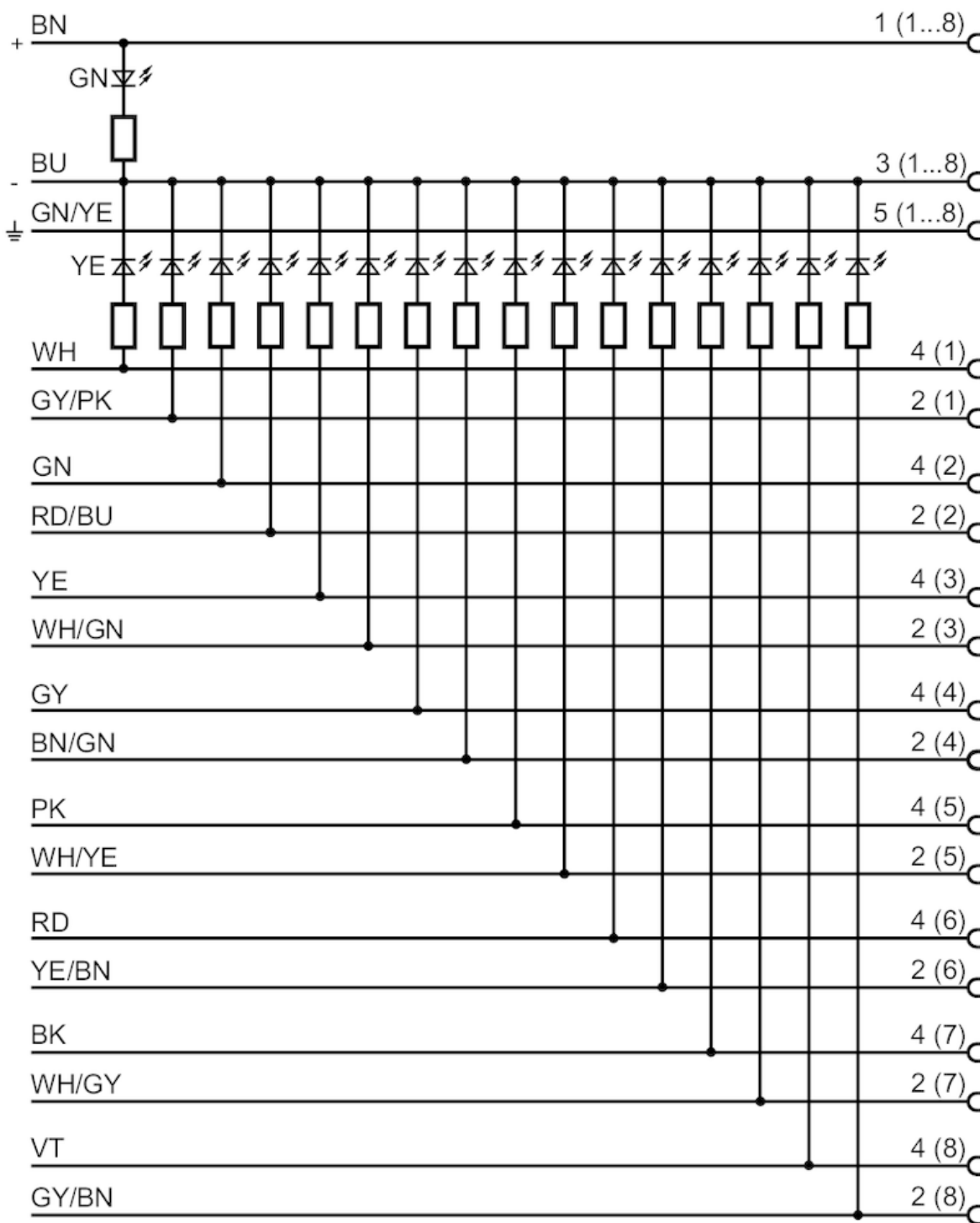

Core colors :

BK = black
 BN = brown
 BU = blue
 GN = green
 GY = grey
 PK = pink
 RD = red
 VT = lilac
 WH = white
 YE = yellow

E12071

Wiring block

ZDO8H05HMSS0020B19

