

E12079




Female cordset

ADOGH050MSS0010C05

Article no longer available - archive entry

Alternative articles: EVC534

When selecting an alternative article and accessories please note that technical data may differ!

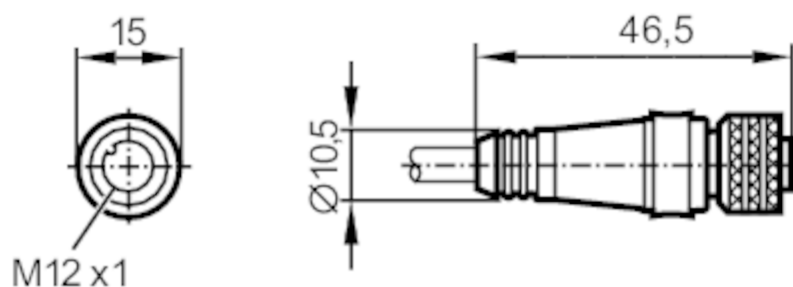

Application

System	Free from silicone; Halogen-free; gold-plated contacts; screened cable
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Protection class		III
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...80
Protection		IP 67

Mechanical data

Weight	[g]	455.4
Dimensions	[mm]	15 x 15 x 46.5
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E12079



Female cordset


ADOGH050MSS0010C05

Electrical connection


Cable: 10 m, PUR, Halogen-free, black, Ø 5.5 mm, screened; 5 x 0.25 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.5 Nm; Shielded connection cable: shield not connected

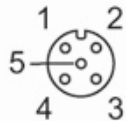

Connection

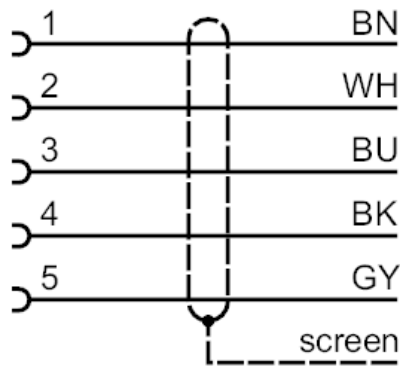

	Core colors :
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white