


E12090



Ethernet connection cable

VSTGN040ZDS0002L04STGP040--S

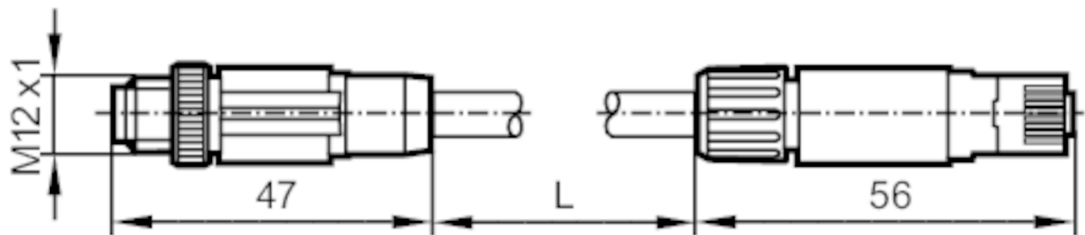

Application

System	screened cable
Design	Ethernet cable, D-coded
Application	Cross-over patch cable; Patch cable

Operating conditions

Ambient temperature	[°C]	-25...70
Protection		IP 67; IP 20; (M12 plug / RJ45 plug)

Mechanical data

Weight	[g]	166.7
Material		TPU / PA
Molded-body material		PA / TPU (urethane)
Material nut		diecast zinc, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug M12

Connector: 1 x M12, straight; coding: D; Moulded body: PA; Locking: diecast zinc, nickel-plated; Tightening torque: 0.7...0.9 Nm



E12090




Ethernet connection cable

VSTGN040ZDS0002L04STGP040--S

Electrical connection

Cable: 2 m, PVC, green, Ø 6.5 mm, screened; 2 x 2 x 0.38 mm²

Connection

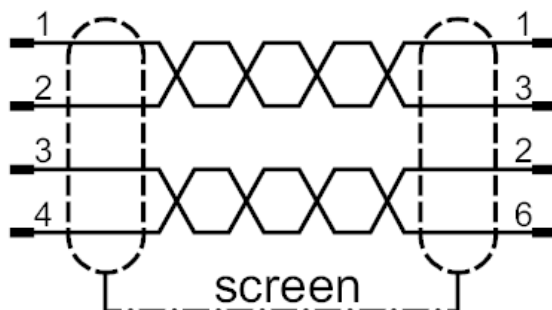

Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Moulded body: TPU (urethane)

